
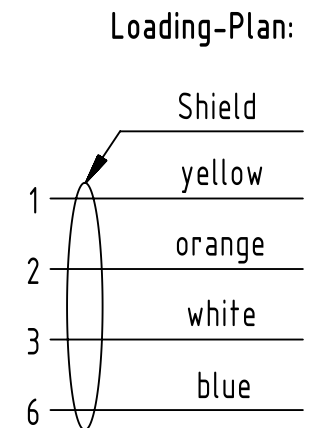
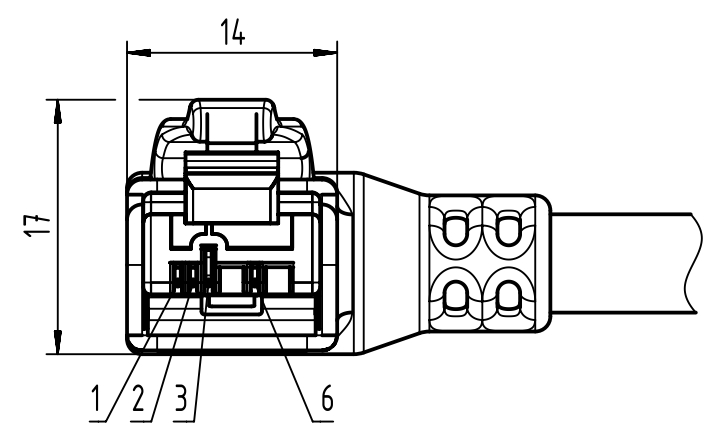
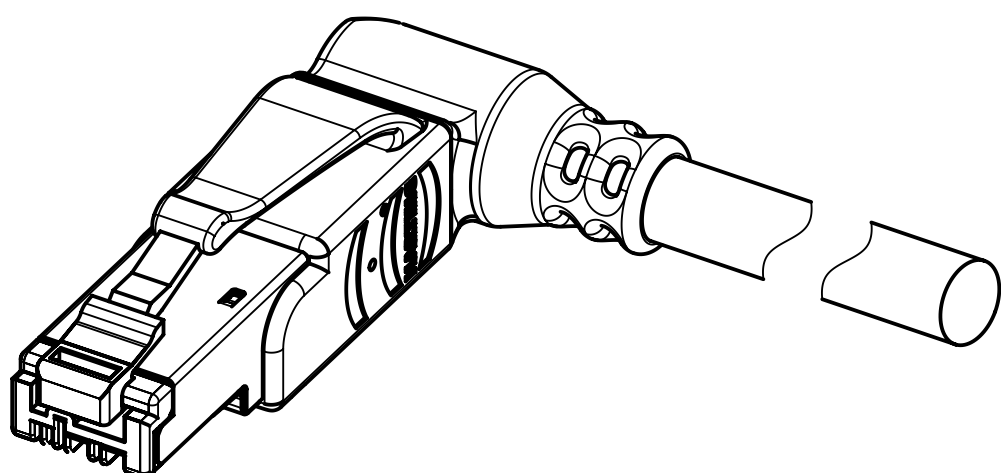


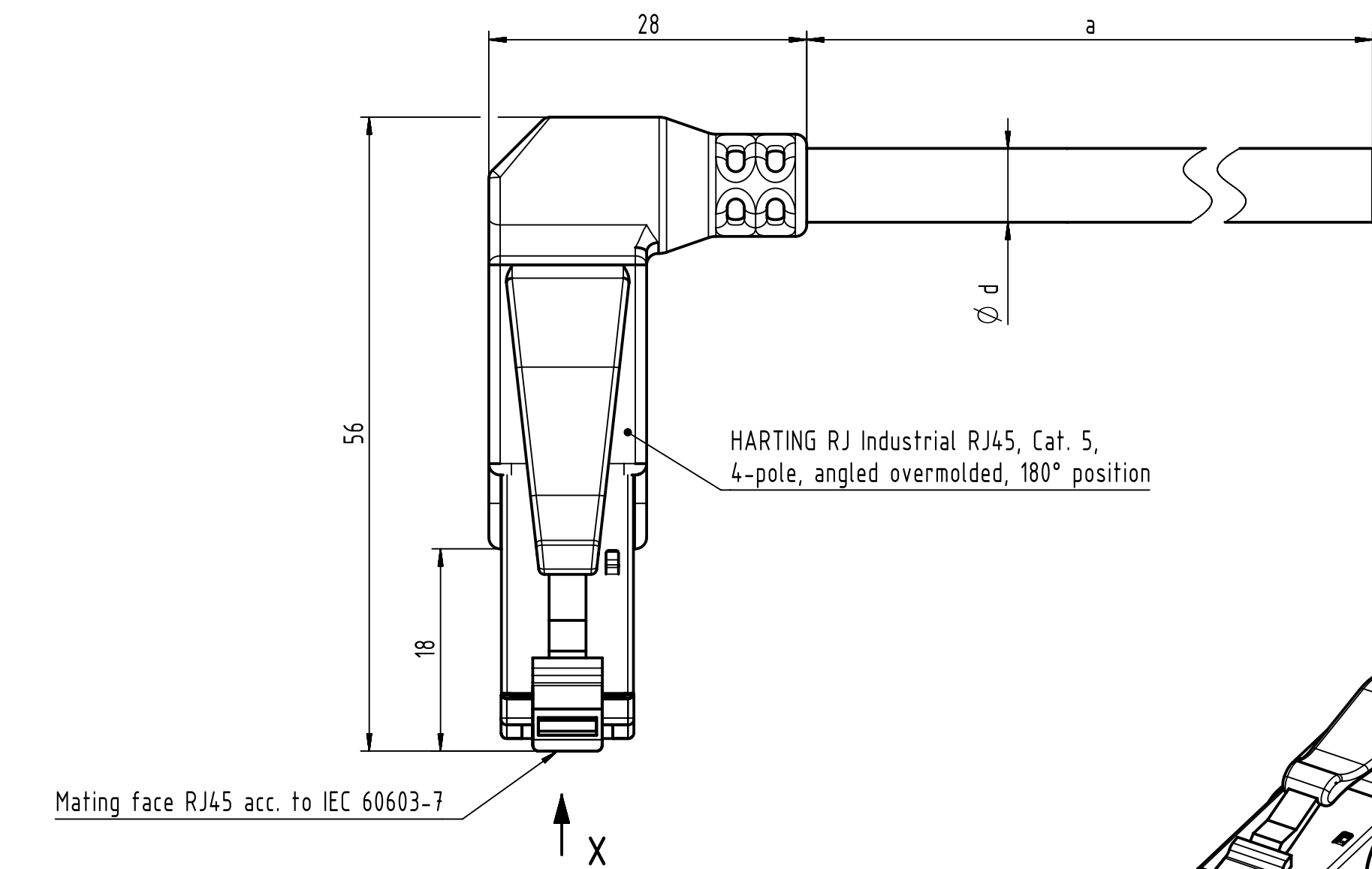

- Protection level: IP20
- Temperature range: -40°C ... +70°C

		All Dimensions in mm Original Size DIN A3		Scale 2:1		Free size tol.		Ref.					
								Sub.					
		All rights reserved		Created by MUNTEANV		Inspected by AVRAM		Standardisation HOFFMANN		Date 2016-01-25		State Final Release	
		Department EC PD - RO											
HARTING Electronics GmbH D-32339 Espelkamp		Title RJ Industrial Cable Assembly										Doc-Key / ECM-Nr. 100081066/UGD/014/D 500000099449	
		Type TB		Number 094705000XX								Rev. D	

1		2		3		4		5		6		7		8											
A	52	09470500052		RJ45 Ethernet trailing cable, AWG22/7, 2x2x0.75, PUR, Cat. 5+, green				6.5±0.2		6	RJ45 Ha-VIS EtherRail flexible data cable, AWG 22/7, 4x0.25, Cat. 5/5e, black					6.6±0.2	1.5								
	51	09470500051								5															
	50	09470500050								4															
	49	09470500049								3															
	48	09470500048								2															
	47	09470500047								1.5															
	46	09470500046								1															
	45	09470500045								0.5															
	44	09470500044								100															
	43	09470500043								90															
B	42	09470500042		RJ45 Ethernet stranded cable, 4xAWG22/7, PVC, Cat. 5+, green				6.5±0.2		80	RJ45 Ethernet stranded cable, AWG22/7, 2x2x0.75, outdoor, PVC, Cat. 5+, black					80									
	41	09470500041								70						70									
	40	09470500040								60						60									
	39	09470500039								50						50									
	38	09470500038								40						40									
	37	09470500037								30						30									
	36	09470500036								20						20									
	35	09470500035								15						15									
	34	09470500034								10						10									
	33	09470500033								9						9									
C	32	09470500032		RJ45 Ethernet standard cable, AWG22/1, 2x2x0.64, PVC, Cat. 5+, green				6.5±0.2		8	RJ45 Ethernet trailing cable, AWG22/7, 2x2x0.75, PUR, Cat. 5+, green					8									
	31	09470500031								7						7									
	30	09470500030								6						6									
	29	09470500029								5						5									
	28	09470500028								4						4									
	27	09470500027								3						3									
	26	09470500026								2						2									
	25	09470500025								1.5						1.5									
	24	09470500024								1						1									
	23	09470500023								0.5						0.5									
D	22	09470500022		RJ45 Ethernet standard cable, AWG22/1, 2x2x0.64, PVC, Cat. 5+, green				6.5±0.2		100	RJ45 Ethernet trailing cable, AWG22/7, 2x2x0.75, PUR, Cat. 5+, green					100									
	21	09470500021								90						90									
	20	09470500020								80						80									
	19	09470500019								70						70									
	18	09470500018								60						60									
	17	09470500017								50						50									
	16	09470500016								40						40									
	15	09470500015								30						30									
	14	09470500014								20						20									
	13	09470500013								15						15									
E	12	09470500012		RJ45 Ethernet standard cable, AWG22/1, 2x2x0.64, PVC, Cat. 5+, green				6.5±0.2		10	RJ45 Ethernet trailing cable, AWG22/7, 2x2x0.75, PUR, Cat. 5+, green					10									
	11	09470500011								9						9									
	10	09470500010								8						8									
	9	09470500009								7						7									
	8	09470500008								6						6									
	7	09470500007								5						5									
	6	09470500006								4						4									
	5	09470500005								3						3									
	4	09470500004								2						2									
	3	09470500003								1.5						1.5									
F	2	09470500002		RJ45 Ethernet standard cable, AWG22/1, 2x2x0.64, PVC, Cat. 5+, green				6.5±0.2		1	RJ45 Ethernet trailing cable, AWG22/7, 2x2x0.75, PUR, Cat. 5+, green					1									
	1	09470500001								0.5						0.5									
	Cont. no.	Part no.								Type of cable						Dim. d [mm]	Dim. a [m]								

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[09470500002](#) [09470500023](#) [09470500024](#) [09470500025](#) [09470500026](#) [09470500027](#) [09470500029](#)
[09470500045](#) [09470500046](#) [09470500047](#) [09470500048](#) [09470500049](#) [09470500051](#) [09470500031](#) [09470500034](#)
[09470500056](#) [09470500054](#) [09470500035](#) [09470500012](#) [09470500004](#) [09470500059](#) [09470500013](#)
[09470500057](#) [09470500060](#) [09470500058](#)