


Connector Location A


Connector Location B

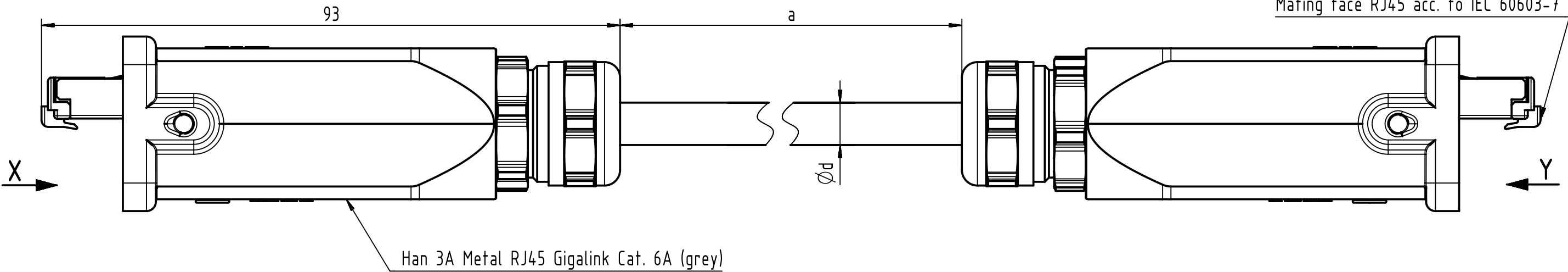




- Protection level: IP67/65
- Temperature range: -20°C ... +80°C

X  
male

Y  
male

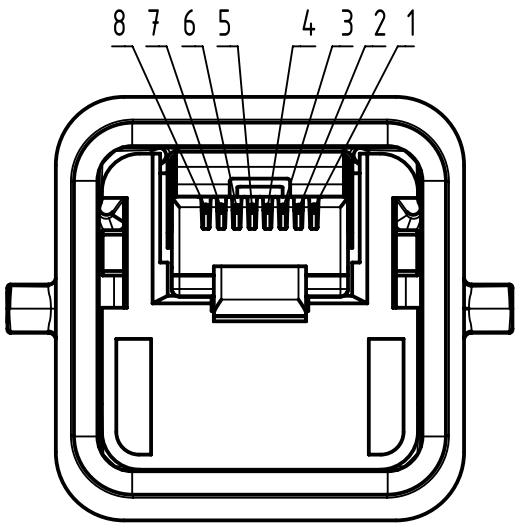

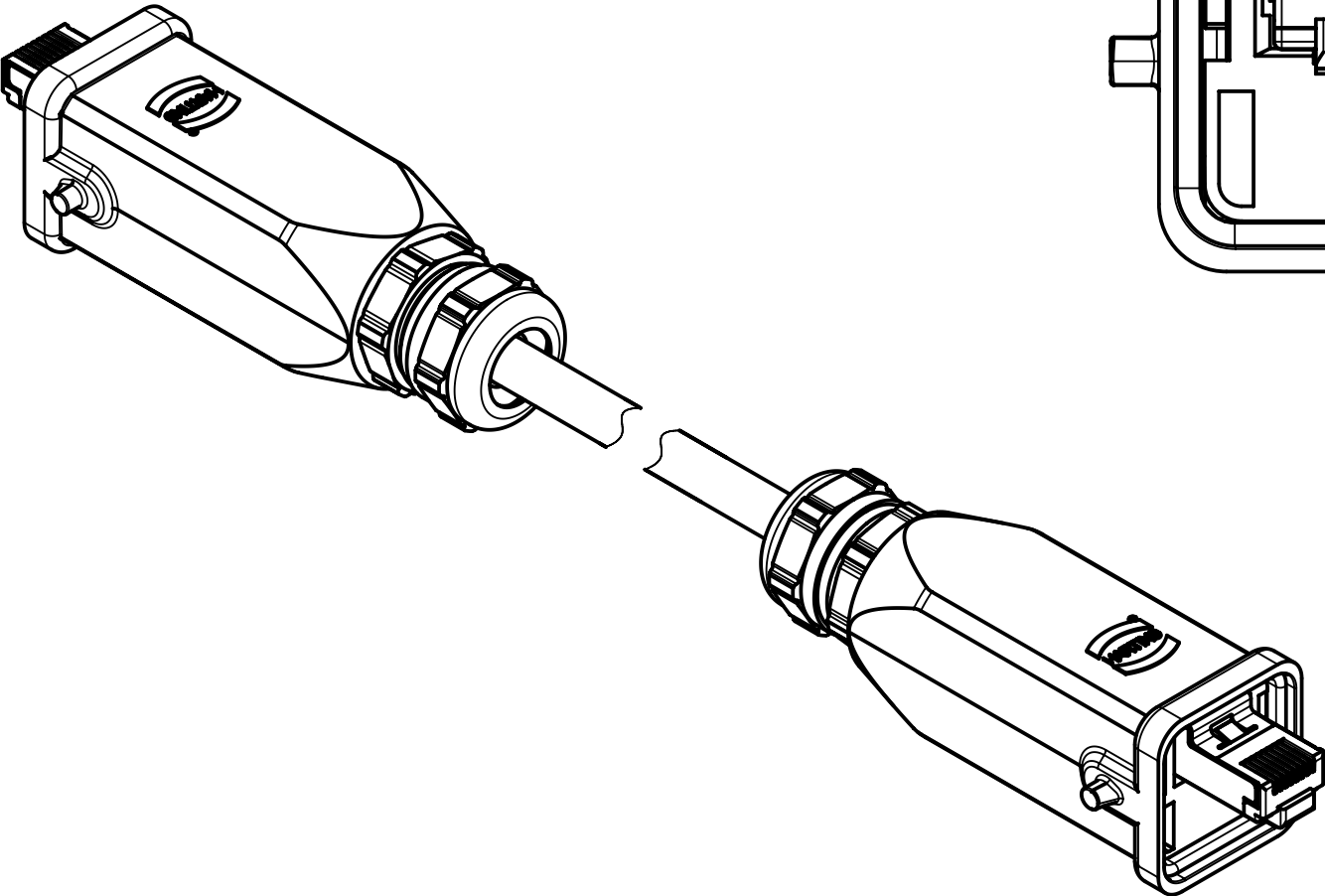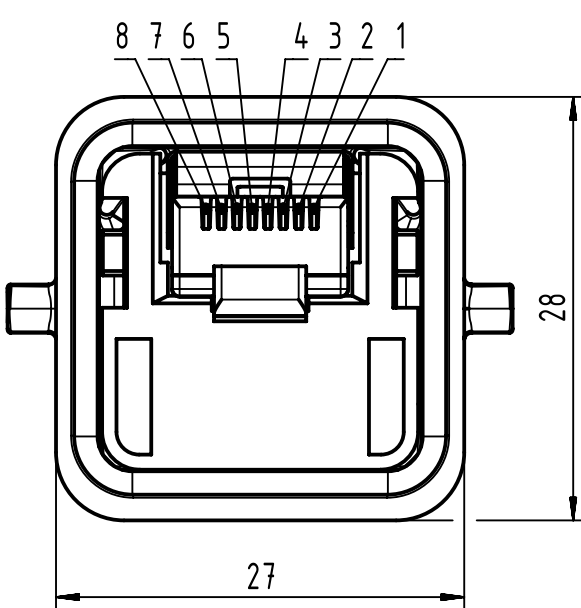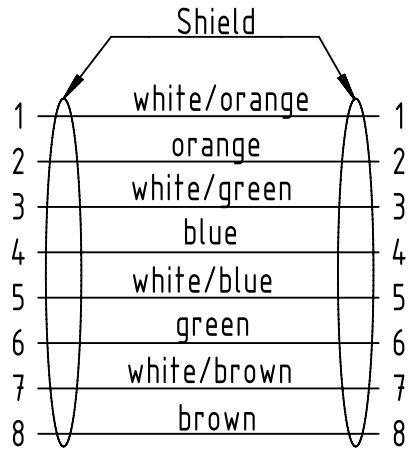

Loading-Plan  
acc. to TIA/EIA 568B



All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing 2016-09-14	
	All rights reserved	Created by POPESCU	Inspected by TAMAS	Standardisation MUNTEANV	Date 2016-09-15	State Final Release	
	Department HCS - RO	Title RJ Industrial Cable Assembly				Doc-Key / ECM-Nr. 100155415/UGD/012/G 500000108934	
HARTING Customised Solutions D-32427 Minden		Type TB	Number 094571515XX			Rev. G	Page 1/2

1		2		3		4		5		6		7		8			
A	36	09457151578		RJ45 Ethernet stranded cable, AWG 26/7, 4x2x0.5/1.0, Cat. 6A, PUR, yellow		Ø6.7		100								A	
	35	09457151577						40									
	34	09457151576						30									
	33	09457151575						25									
	32	09457151574						20									
	31	09457151573						15									
	30	09457151572						10									
	B	29	09457151571					9									
		28	09457151570					8									
		27	09457151569					7									
		26	09457151568					6									
		25	09457151567					5									
		24	09457151566					4									
	C	23	09457151565					3									
		22	09457151564					2									
		21	09457151563					1.5									
		20	09457151562					1									
		19	09457151561					0.5									
D		18	09457151553		RJ45 Ethernet stranded cable, AWG 26/7, 4x2x0.5/1.0, Cat. 6A, PVC, yellow		Ø6.6		20								D
	17	09457151552		15													
	16	09457151551		10													
	15	09457151532		30													
	14	09457151531		9													
	13	09457151530		8													
	12	09457151529		7													
	E	11	09457151528						6								
		10	09457151527						5								
		9	09457151535						4.4								
		8	09457151526						4								
		7	09457151534						3.4								
		6	09457151525						3								
	F	5	09457151533						2.2								
		4	09457151524						2								
		3	09457151523						1.5								
		2	09457151522						1								
		1	09457151521						0.5								
Cont. no.		Part-no.		Type of cable		Dim. d [mm]		Dim. a[m]									

50	09457151594	RJ45 Ethernet stranded cable, 4x2xAWG 26/7, PVC, outdoor, Cat. 6A, black		Ø6.6		20	
49	09457151593					15	
48	09457151592					10	
47	09457151591					9	
46	09457151590					8	
45	09457151589					7	
44	09457151588					6	
43	09457151587					5	
42	09457151586					4	
41	09457151585					3	
40	09457151584					2	
39	09457151583					1.5	
38	09457151582					1	
37	09457151581					0.5	
Cont. no.	Part-no.	Type of cable		Dim. d [mm]		Dim. a[m]	

		All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing 2016-09-14	
		All rights reserved		Created by POPESCU		Inspected by TAMAS		Standardisation MUNTEANV	
Department HCS - RO		Title RJ Industrial Cable Assembly		Date 2016-09-15		State Final Release		Doc-Key / ECM-Nr. 100155415/UGD/012/G 500000108934	
HARTING Customised Solutions D-32427 Minden		Type TB		Number 094571515XX		Rev. G		Page 2/2	

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

09457151553