
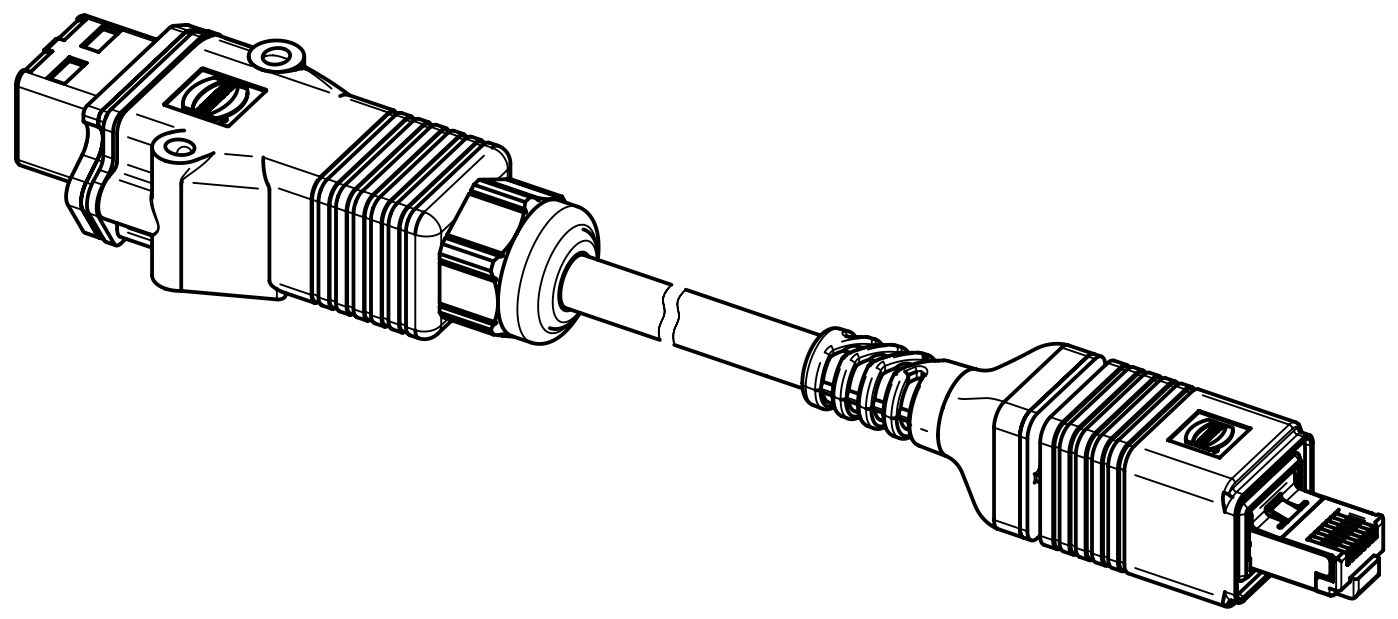
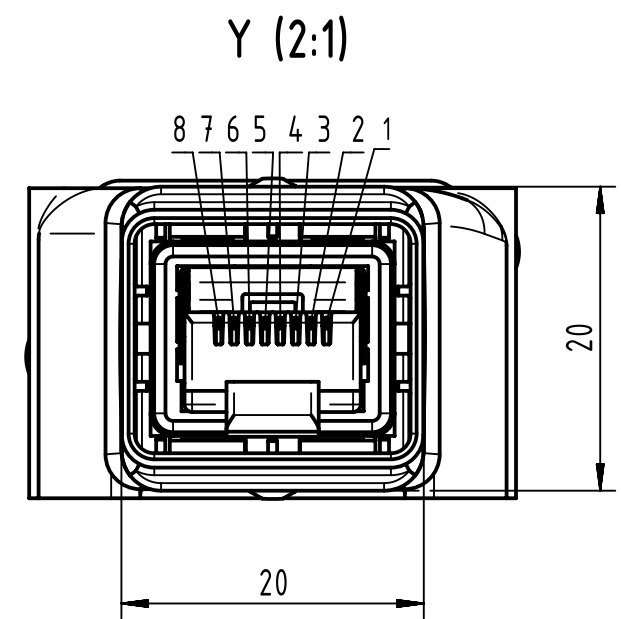
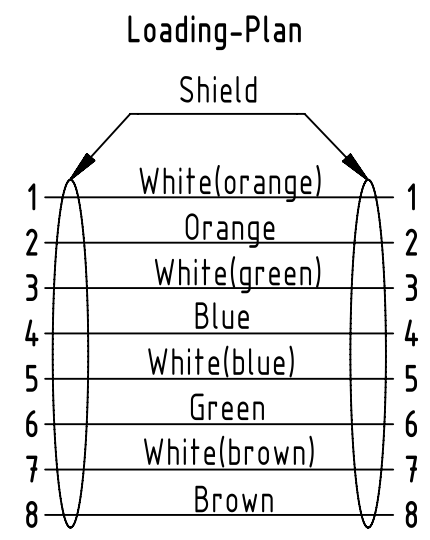
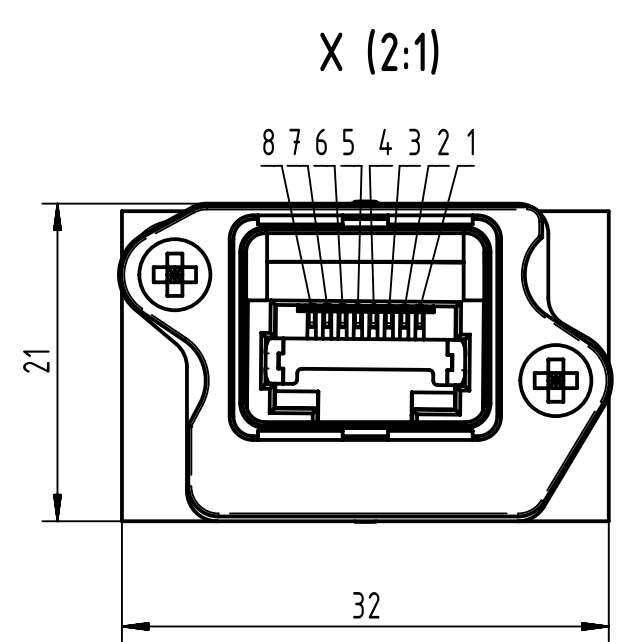


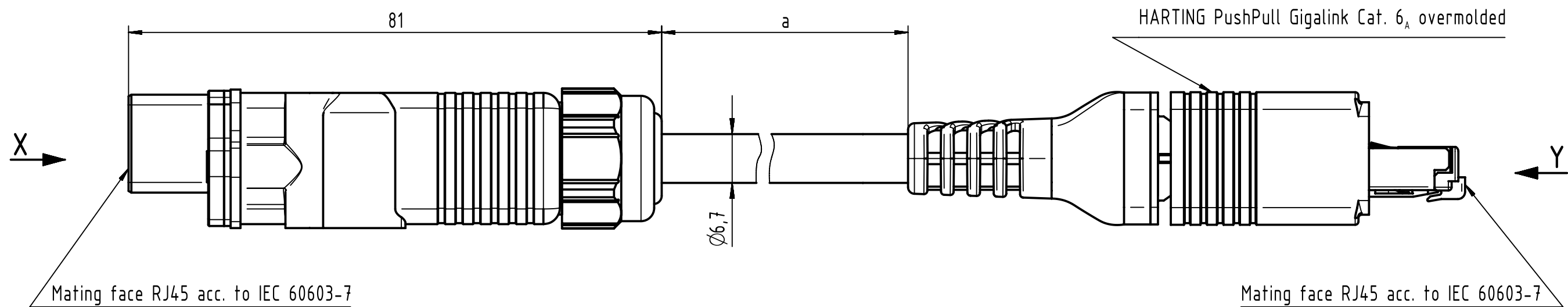

-Transmission properties in accordance with ISO/IEC 11801: Class E
-Temperature range: -35°C ...+70°C

	All Dimensions in mm Original Size DIN A3		Scale 1.5:1	Free size tol.		Ref.	
						Sub.	
	All rights reserved		Created by TAMAS	Inspected by AVRAM	Standardisation HOFFMANN	Date 2014-01-24	State Final Release
	Department EC PD - RO		Title HARTING PushPull RJ45 Cable Assembly				Doc-Key / ECM-Nr. 100523352/UGD/001/B 500000069669
	HARTING Electronics GmbH D-32339 Espelkamp		Type TB	Number 3345232XXX0003			Rev. B Page 1/2

1	2	3	4	5	6	7	8	
A								A
B								B
C								C
D								D
E								E
F								F
1	2	3	4	5	6	7	8	

19	33452321000003	4x2 AWG 26/7, PUR	10
18	33452320800003		8
17	33452320750003		7.5
16	33452320500003		5
15	33452320400003		4
14	33452320350003		3.5
13	33452320300003		3
12	33452320250003		2.5
11	33452320200003		2
10	33452320150003		1.5
9	33452320100003		1
8	33452320090003		0.9
7	33452320080003		0.8
6	33452320070003		0.7
5	33452320060003		0.6
4	33452320050003		0.5
3	33452320040003		0.4
2	33452320030003		0.3
1	33452320020003		0.2
Cont. No.	Part-no.	Type of cable	Dim. a [m]

	All Dimensions in mm Original Size DIN A3		Scale 1:1		Free size tol.		Ref. Sub.			
	All rights reserved Department EC PD - RO		Created by TAMAS		Inspected by AVRAM		Standardisation HOFFMANN			
HARTING Electronics GmbH D-32339 Espelkamp		Title HARTING PushPull RJ45 Cable Assembly					Date 2014-01-24		State Final Release	
		Type TB					Number 3345232XXX0003		Doc-Key / ECM-Nr. 100523352/UGD/001/B 500000069669	
							Rev. B		Page 2/2	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

<u>33452320800003</u>	<u>33452320100003</u>	<u>33452320070003</u>	<u>33452320250003</u>	<u>33452321000003</u>	<u>33452320040003</u>
<u>33452320050003</u>	<u>33452320060003</u>	<u>33452320400003</u>	<u>33452320750003</u>	<u>33452320090003</u>	<u>33452320200003</u>
<u>33452320350003</u>	<u>33452320030003</u>	<u>33452320500003</u>	<u>33452320150003</u>	<u>33452320080003</u>	<u>33452320300003</u>