



Pushing Performance  
Since 1945

# har-modular fixing rail 101.50

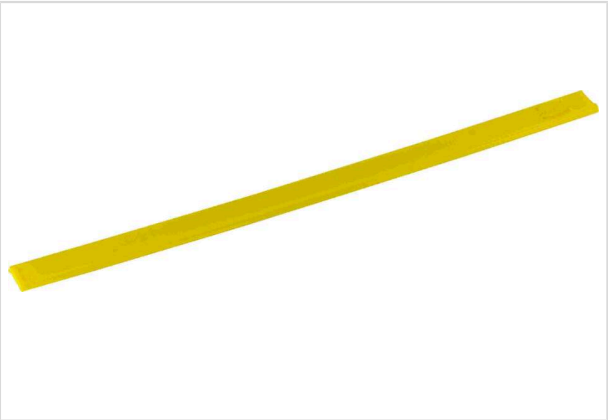


Image is for illustration purposes only. Please refer to product description.

Part number	02 09 500 1020
Specification	har-modular fixing rail 101.50
HARTING eCatalogue	<a href="https://b2b.harting.com/02095001020">https://b2b.harting.com/02095001020</a>

## Identification

Category	Accessories
Series	har-modular®
Type of accessory	Fixing rail

## Technical characteristics

Length	101.5 mm
Limiting temperature	-55 ... +125 °C
Isolation group	I (600 ≤ CTI)
Moisture Sensitivity Level (MSL)	1 acc. to ECA/IPC/JEDEC J-STD-020D

## Material properties

Material (accessories)	Polyamide (PA)
Colour (accessories)	Yellow
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R26



**Pushing Performance**  
Since 1945

Specifications and approvals

UL / CSA	UL 1977 ECBT2.E102079
	CSA-C22.2 No. 182.3 ECBT8.E102079

Commercial data

Packaging size	100
Net weight	0.73 g
Country of origin	Romania
European customs tariff number	85389099
GTIN	5713140216143
ETIM	EC002943
eCl@ss	27440292 Connector component (accessories)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[02095001020](#)