



Pushing Performance  
Since 1945

# Han-Fast Lock 1,5-2,5mm² mit Pin, Ag

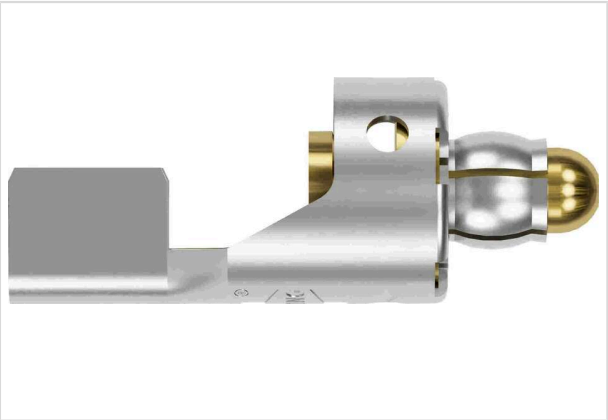


Image is for illustration purposes only. Please refer to product description.

Part number	09 08 000 7122
Specification	Han-Fast Lock 1,5-2,5mm² mit Pin, Ag
HARTING eCatalogue	<a href="https://b2b.harting.com/09080007122">https://b2b.harting.com/09080007122</a>

## Identification

Category	Contacts
Series	Han-Fast® Lock
Type of contact	PCB contact
Description of the contact	With pin

## Version

Pack contents	Single contact
---------------	----------------

## Technical characteristics

Conductor cross-section	1.5 ... 2.5 mm²
Rated current	≤60 A
Contact resistance	≤2 mΩ
Stripping length	7.5 mm

## Material properties

Material (contacts)	Copper alloy
Surface (contacts)	Silver plated
Material (locking)	Copper alloy
Surface (locking)	Passivated
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption
China RoHS	50



Pushing Performance  
Since 1945

Material properties

REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Yes
REACH SVHC substances	Lead
ECHA SCIP number	b51e5b97-eeb5-438b-8538-f1771d43c17d
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead
	Nickel

Commercial data

Packaging size	100
Net weight	2.04 g
Country of origin	Germany
European customs tariff number	85366990
GTIN	5713140014862
ETIM	EC002637
eCl@ss	27460201 PCB connector (board connector)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09080007122](#)