

## Han Fast-Lock 4-6qmm ang.silverplat.+pin

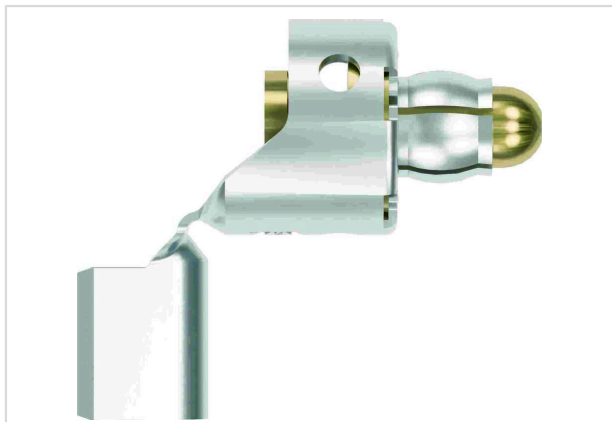


Image is for illustration purposes only. Please refer to product description.

Part number	09 08 000 7223
Specification	Han Fast-Lock 4-6qmm ang.silverplat.+pin
HARTING eCatalogue	<a href="https://b2b.harting.com/09080007223">https://b2b.harting.com/09080007223</a>

### Identification

Category	Contacts
Series	Han-Fast <sup>®</sup> Lock
Type of contact	PCB contact
Description of the contact	With pin Angled

### Version

Pack contents	Single contact
---------------	----------------

### Technical characteristics

Conductor cross-section	4 ... 6 mm <sup>2</sup>
Rated current	≤60 A
Contact resistance	≤2 mΩ
Stripping length	7.5 mm

### Material properties

Material (contacts)	Copper alloy
Surface (contacts)	Silver plated
Material (locking)	Copper alloy
Surface (locking)	Passivated
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption



**Pushing Performance**  
Since 1945

## Material properties

China RoHS	50
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Yes
REACH SVHC substances	Lead
ECHA SCIP number	b51e5b97-eeb5-438b-8538-f1771d43c17d
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead Nickel

## Commercial data

Packaging size	100
Net weight	2.42 g
Country of origin	Germany
European customs tariff number	85366990
GTIN	5713140188624
ETIM	EC002637
eCl@ss	27460201 PCB connector (board connector)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09080007223](#) [9080007223](#)