

Han TC300 female contact 70mm²

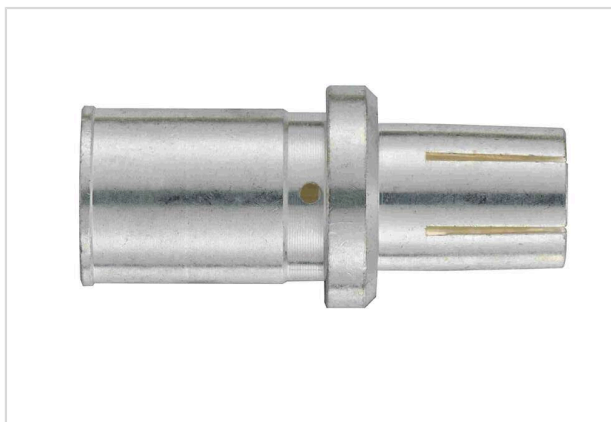


Image is for illustration purposes only. Please refer to product description.

Part number	09 11 000 6635
Specification	Han TC300 female contact 70mm ²
HARTING eCatalogue	https://harting.com/09110006635

Identification

Category	Contacts
Type of contact	Crimp contact

Version

Termination method	Crimp termination
Gender	Female
Manufacturing process	Turned contacts

Technical characteristics

Conductor cross-section	70 mm ²
Rated current	≤300 A
Contact resistance	≤0.3 mΩ
Stripping length	22.5 mm
Limiting temperature	-40 ... +125 °C
Mating cycles	≥500

Material properties

Material (contacts)	Copper alloy
Surface (contacts)	Silver plated
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained



Pushing Performance
Since 1945

Material properties

REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

Specifications and approvals

Specifications	IEC 60664-1 IEC 61984
----------------	--------------------------

Commercial data

Packaging size	2
Net weight	45 g
Country of origin	Germany
European customs tariff number	85366990
GTIN	5713140188419
ETIM	EC000796
eCl@ss	27440204 Contact for industrial connectors

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09110006635](#)