

Han TC300 male contact 95mm²

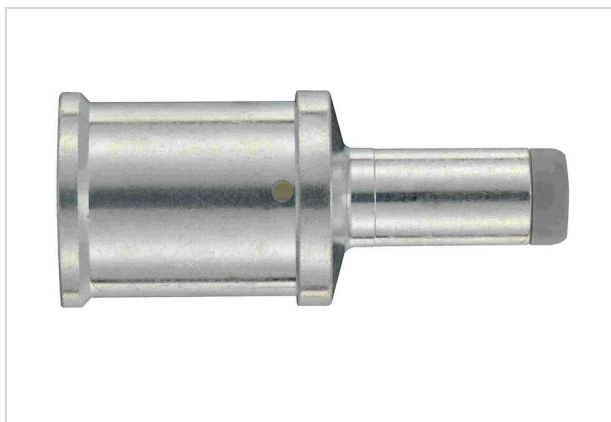


Image is for illustration purposes only. Please refer to product description.

Part number	09 11 000 7536
Specification	Han TC300 male contact 95mm ²
HARTING eCatalogue	https://harting.com/09110007536

Identification

Category	Contacts
Type of contact	Crimp contact

Version

Termination method	Crimp termination
Gender	Male
Manufacturing process	Turned contacts

Technical characteristics

Conductor cross-section	95 mm ²
Rated current	≤300 A
Contact resistance	≤0.3 mΩ
Stripping length	24 mm
Limiting temperature	-40 ... +125 °C
Mating cycles	≥500

Material properties

Material (contacts)	Copper alloy
Surface (contacts)	Silver plated

Specifications and approvals

Specifications	IEC 60664-1 IEC 61984
----------------	--------------------------



Pushing Performance
Since 1945

Commercial data

Packaging size	2
Net weight	48 g
Country of origin	Romania
European customs tariff number	85366990
GTIN	5713140188396
ETIM	EC000796
eCl@ss	27440204 Contact for industrial connectors

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09110007536](#)