

## Han TC300 male contact M8, short

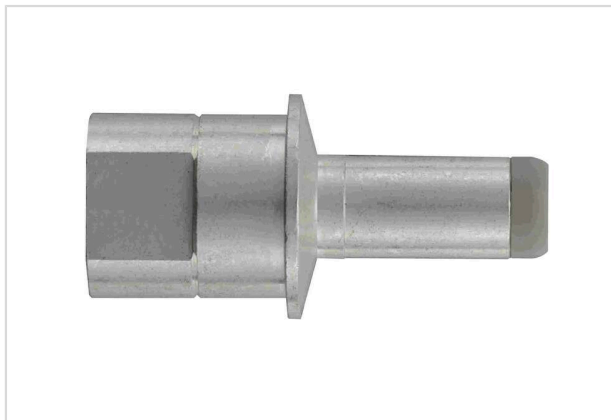


Image is for illustration purposes only. Please refer to product description.

Part number	09 11 000 7579
Specification	Han TC300 male contact M8, short
HARTING eCatalogue	<a href="https://b2b.harting.com/09110007579">https://b2b.harting.com/09110007579</a>

### Identification

Category	Contacts
Series	TC 300
Type of contact	Screw contact
Description of the contact	M8 Short version

### Version

Gender	Male
Manufacturing process	Turned contacts

### Technical characteristics

Rated current	≤300 A
Contact resistance	≤0.3 mΩ
Tightening torque	10 Nm
Wrench size	14
Limiting temperature	-40 ... +125 °C
Mating cycles	≥500

### Material properties

Material (contacts)	Copper alloy
Surface (contacts)	Silver plated
RoHS	compliant
ELV status	compliant



Pushing Performance  
Since 1945

Material properties

China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Yes
REACH SVHC substances	Potassium 1,1,2,2,3,3,4,4,4-nonafluorobutane-1-sulphonate

Specifications and approvals

Specifications	IEC 60664-1 IEC 61984
----------------	--------------------------

Commercial data

Packaging size	1
Net weight	40 g
Country of origin	Romania
European customs tariff number	85366990
GTIN	5713140188532
ETIM	EC000796
eCl@ss	27440204 Contact for industrial connectors

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09110007579](#)