



Pushing Performance
Since 1945

Leiterplatten Adapter Han Q7/0 2,4mm

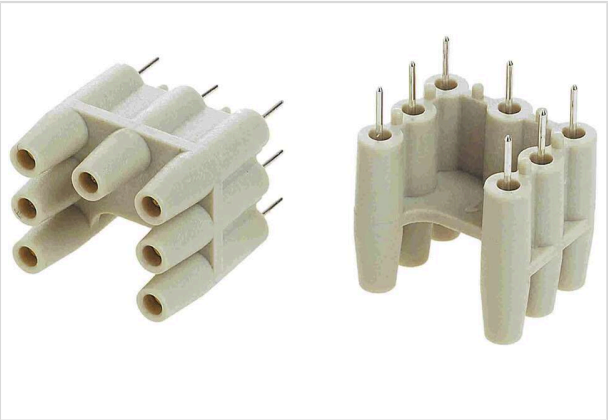


Image is for illustration purposes only. Please refer to product description.

Part number	09 12 000 9908
Specification	Leiterplatten Adapter Han Q7/0 2,4mm
HARTING eCatalogue	https://b2b.harting.com/09120009908

Identification

Category	Accessories
Type of accessory	PCB adapter
Description of the accessory	In the Han [®] Q 7/0

Version

Gender	Female
Details	for PCB's up to 2.4 mm

Technical characteristics

Rated current	7.5 A
Rated voltage	250 V
Rated impulse voltage	4 kV
Pollution degree	3
Limiting temperature	-40 ... +125 °C

Material properties

Material (insert)	Polycarbonate (PC)
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption
China RoHS	50
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained



Pushing Performance
Since 1945

Material properties

REACH SVHC substances	Yes
REACH SVHC substances	Lead
ECHA SCIP number	1e38d35d-d1be-4585-8e03-95faccd739bf
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead Nickel
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R22 (HL 1-3) R23 (HL 1-3)

Commercial data

Packaging size	10
Net weight	2.8 g
Country of origin	Romania
European customs tariff number	85366990
GTIN	5713140016316
ETIM	EC002637
eCl@ss	27460201 PCB connector (board connector)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09120009908](#)