

## Pneumatic contact fem. with valve 3,0 mm

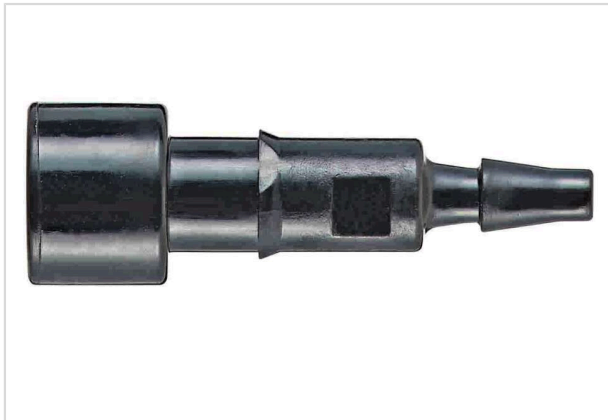


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 000 6257
Specification	Pneumatic contact fem. with valve 3,0 mm
HARTING eCatalogue	<a href="https://harting.com/09140006257">https://harting.com/09140006257</a>

### Identification

Category	Contacts
Type of contact	Pneumatic contact
Description of the contact	With shut-off Polypropylen Straight

### Version

Gender	Female
Manufacturing process	Turned contacts

### Technical characteristics

Limiting temperature	-40 ... +80 °C
Operating pressure	≤8 bar
Tube inner diameter	3 mm

### Material properties

Material (contacts)	Delrin acetal
Material (seal)	Buna-N
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained



Pushing Performance  
Since 1945

Material properties

REACH SVHC substances	Not contained
-----------------------	---------------

Specifications and approvals

UL / CSA	UL 1977 ECBT2.E235076
	CSA-C22.2 No. 182.3 ECBT8.E235076

Commercial data

Packaging size	10
Net weight	0.6 g
Country of origin	Germany
European customs tariff number	39269097
GTIN	5713140018419
ETIM	EC000796
eCl@ss	27440204 Contact for industrial connectors

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09140006257](#)