

Pneum. contact metal ID 4 male

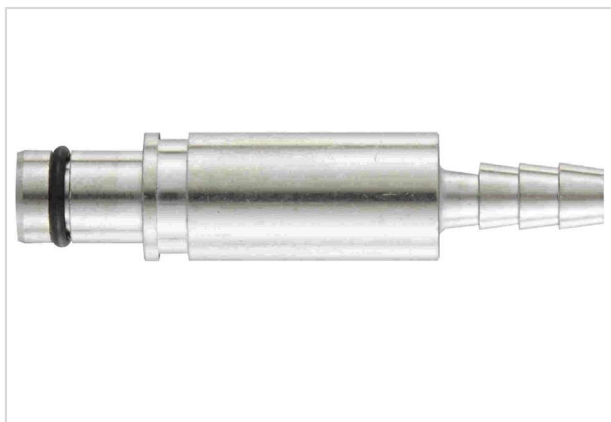


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 000 6304
Specification	Pneum. contact metal ID 4 male
HARTING eCatalogue	https://harting.com/09140006304

Identification

Category	Contacts
Type of contact	Pneumatic contact
Description of the contact	Without shut-off Straight
Features	The Han® Pneumatic contacts without shut-off are suitable for the use inside a vacuum. (Limit: 100 mbar = 100 hPa ≈ approx 90% vacuum)

Version

Gender	Male
Manufacturing process	Turned contacts

Technical characteristics

Limiting temperature	-40 ... +85 °C
Operating pressure	≤10 bar
Tube inner diameter	4 mm

Material properties

Material (contacts)	Brass
Material (seal)	HNBR (hydrated NBR)
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained



Pushing Performance
Since 1945

Material properties

REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Nickel

Specifications and approvals

UL / CSA	UL 1977 ECBT2.E235076
	CSA-C22.2 No. 182.3 ECBT8.E235076

Commercial data

Packaging size	10
Net weight	8 g
Country of origin	Romania
European customs tariff number	39269097
GTIN	5713140162778
ETIM	EC000796
eCl@ss	27440204 Contact for industrial connectors

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09140006304](#)