

## Han-Modular Flexbox hood 4 entries

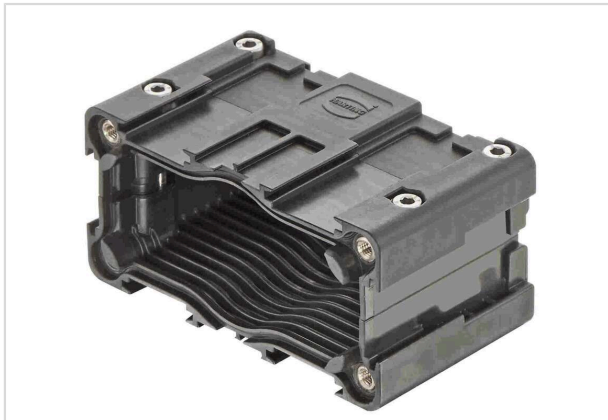


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 000 8014
Specification	Han-Modular Flexbox hood 4 entries
HARTING eCatalogue	<a href="https://harting.com/09140008014">https://harting.com/09140008014</a>

### Identification

Category	Hoods / Housings
Series of hoods/housings	Han-Modular® Flexbox
Type of hood/housing	Hood

### Version

Version	Top entry
Number of cable entries	4
Cable entry	4x

### Technical characteristics

Limiting temperature	-40 ... +125 °C
Note on the limiting temperature	For use as a connector according to IEC 61984.
Degree of protection acc. to IEC 60529	IP54
Clamping range	4 ... 16 mm

### Material properties

Material (hood/housing)	Polyamide (PA) Fibre-glass reinforced
Colour (hood/housing)	RAL 9005 (jet black)
Material (seal)	NBR
Colour (seal)	RAL 9005 (jet black)
Material flammability class acc. to UL 94	V-0
RoHS	compliant



**Pushing Performance**  
Since 1945

## Material properties

ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R22 (HL 1-3)
	R23 (HL 1-3)

## Specifications and approvals

Specifications	IEC 61984
	EN 45545-1
	EN 45545-2

## Commercial data

Packaging size	1
Net weight	112.4 g
Country of origin	China
European customs tariff number	85389099
GTIN	5713140182028
ETIM	EC000437
eCl@ss	27440202 Shell for industrial connectors

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09140008014](#)