

# Han Dummy Module (500 pcs)

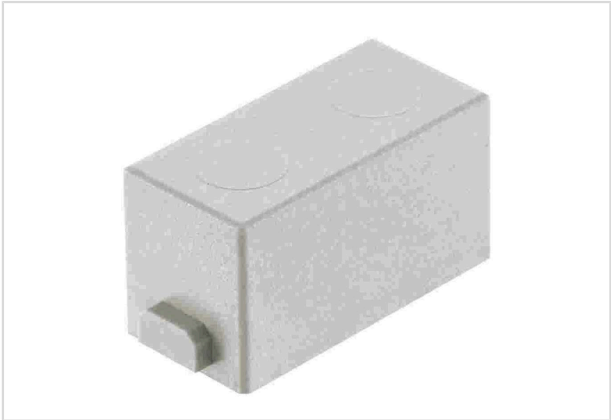


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 000 9950 XL
Specification	Han Dummy Module (500 pcs)
HARTING eCatalogue	<a href="https://b2b.harting.com/09140009950XL">https://b2b.harting.com/09140009950XL</a>

## Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® Dummy module
Size of the module	Single module

## Version

Gender	Male
	Female

## Technical characteristics

Limiting temperature	-40 ... +125 °C
Mating cycles	≥500

## Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained



Pushing Performance  
Since 1945

Material properties

California Proposition 65 substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R22 (HL 1-3) R23 (HL 1-3)

Commercial data

Packaging size	500
Net weight	3.2 g
Country of origin	Germany
European customs tariff number	85366990
GTIN	5713140018785
ETIM	EC002939
eCl@ss	27440392 Connector (accessories)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09140009950XL](#)