



Pushing Performance
Since 1945

Han M12 Module, female (shield-GND)

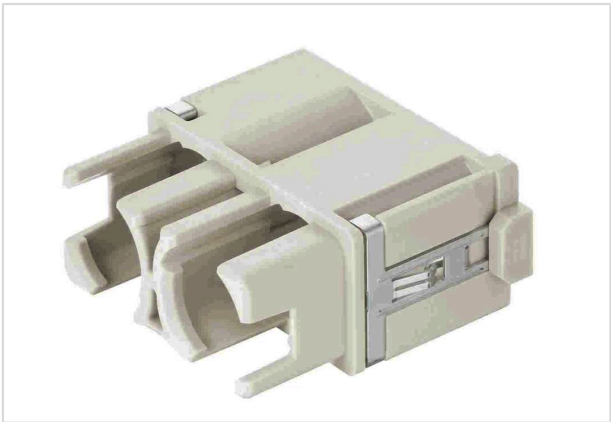


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 002 3162
Specification	Han M12 Module, female (shield-GND)
HARTING eCatalogue	https://b2b.harting.com/09140023162

Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® M12 module
Size of the module	Single module

Version

Gender	Female
Details	With additional shield connection to the hinged frame Please order insert separately.

Technical characteristics

Limiting temperature	-40 ... +85 °C
Mating cycles	≥500

Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained



Pushing Performance
Since 1945

Material properties

REACH SVHC substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R22 (HL 1-3)
	R23 (HL 1-3)

Specifications and approvals

Specifications	IEC 60664-1
	IEC 61984

Commercial data

Packaging size	2
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140184855
ETIM	EC002312
eCl@ss	27440207 Adapter for industrial connectors (module/contact insert)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09140023162](#)