

# Han LC-module-M

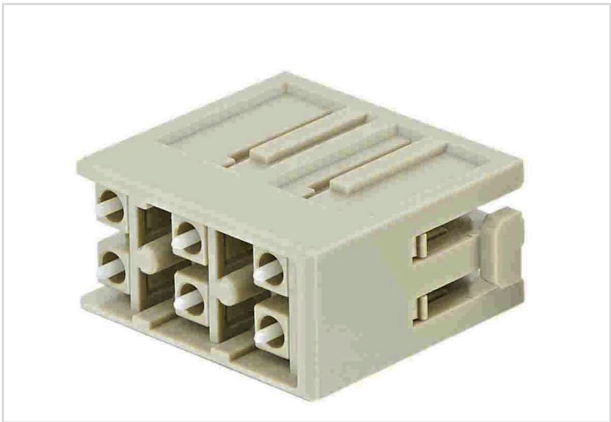


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 006 4701
Specification	Han LC-module-M
HARTING eCatalogue	<a href="https://b2b.harting.com/09140064701">https://b2b.harting.com/09140064701</a>

## Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® LC module
Size of the module	Single module
Features	Suitable for LC contacts

## Version

Gender	Male
Number of contacts	6
Details	Please order contacts separately.

## Technical characteristics

Limiting temperature	-40 ... +85 °C
Mating cycles	≥500

## Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained



**Pushing Performance**  
Since 1945

## Material properties

REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R22 (HL 1-3)
	R23 (HL 1-3)

## Commercial data

Packaging size	2
Net weight	6 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140020542
ETIM	EC000438
eCl@ss	27440219 Module for industrial connectors (FO)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09140064701](#)