

Docking Frame for 4 modules, float mount

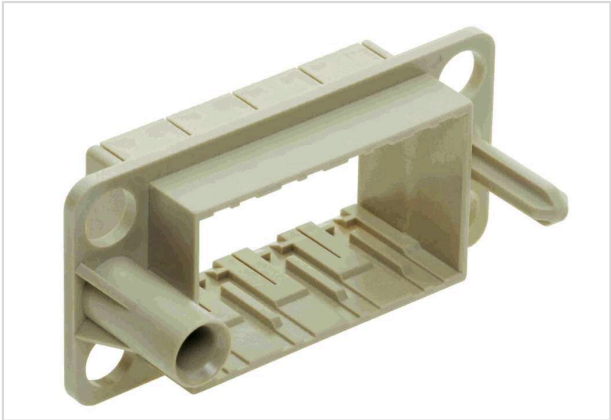


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 016 1701
Specification	Docking Frame for 4 modules, float mount
HARTING eCatalogue	https://b2b.harting.com/09140161701

Identification

Category	Accessories
Series	Han-Modular®
Type of accessory	Docking frame
Description of the accessory	Float mount for 4 modules A ... D

Technical characteristics

Limiting temperature	-40 ... +125 °C
Mating cycles	≥10,000
Note on the mating cycles	Mating cycles with other HMC components
Degree of protection acc. to IEC 60529	IP20
Floating tolerance	±2 mm
Lock-in range	±4 mm

Material properties

Material	Polycarbonate (PC)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained



Pushing Performance
Since 1945

Material properties

Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R22 (HL 1-3)
	R23 (HL 1-3)

Specifications and approvals

Specifications	IEC 60664-1
	IEC 61984

Commercial data

Packaging size	2
Net weight	20 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140021112
ETIM	EC002312
eCl@ss	27440206 Module carrier frame for industrial connectors

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09140161701](#)