



Pushing Performance  
Since 1945

# Han hinged frame plus, for 8 modules A-H

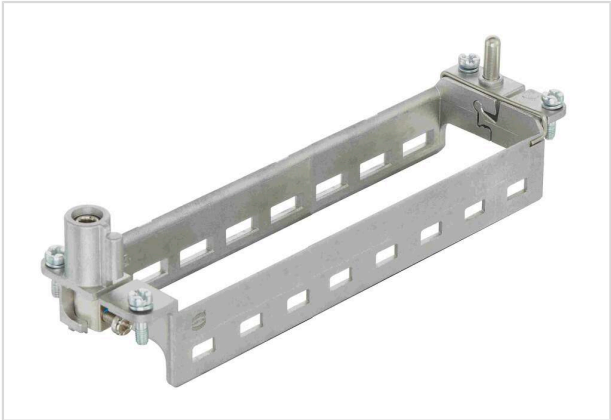


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 032 0361
Specification	Han hinged frame plus, for 8 modules A-H
HARTING eCatalogue	<a href="https://b2b.harting.com/09140320361">https://b2b.harting.com/09140320361</a>

## Identification

Category	Accessories
Series	Han-Modular®
Type of accessory	Hinged frame plus
Description of the accessory	for 8 modules A ... H
Features	Conductor cross-section PE (power side) 4 ... 10 mm <sup>2</sup> Conductor cross-section PE (signal side) 1 ... 2.5 mm <sup>2</sup>

## Version

Size	L32 B
------	-------

## Technical characteristics

Stripping length	8 ... 10 mm
Limiting temperature	-40 ... +125 °C
Mating cycles	≥500

## Material properties

Material	Zinc die-cast Stainless steel
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption
China RoHS	50
REACH Annex XVII substances	Not contained



**Pushing Performance**  
Since 1945

## Material properties

REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Yes
REACH SVHC substances	Lead
ECHA SCIP number	564b7d75-7bf6-4cfb-acb1-2168eb61b675
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead

## Specifications and approvals

Specifications	IEC 60664-1
	IEC 61984
Approvals	DNV GL

## Commercial data

Packaging size	1
Net weight	105 g
Country of origin	China
European customs tariff number	85389099
GTIN	5713140194656
ETIM	EC002312
eCl@ss	27440206 Module carrier frame for industrial connectors

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09140320361](#)