

Han 3 Quintax-M-c

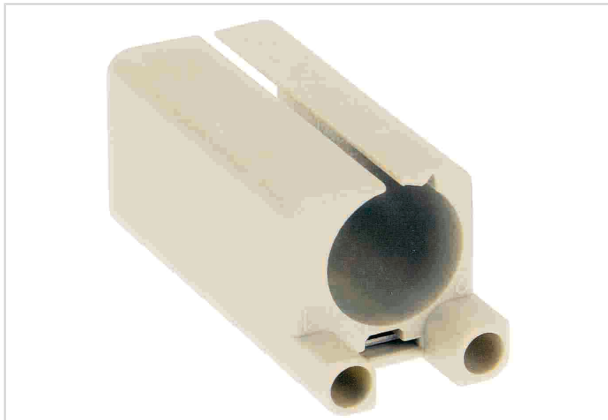


Image is for illustration purposes only. Please refer to product description.

Part number	09 15 003 3001
Specification	Han 3 Quintax-M-c
HARTING eCatalogue	https://b2b.harting.com/09150033001

Identification

Category	Inserts
Series	Han-Brid [®]
Identification	Han-Brid [®] Quintax 3 A

Version

Termination method	Crimp termination
Gender	Male
Size	3 A
Number of contacts	1
	4
	8
further contacts	+ shielding + 2 power contacts
Details	Please order crimp contacts separately.

Technical characteristics

Conductor cross-section	0.14 ... 2.5 mm ²
Insulation resistance	>10 ¹⁰ Ω
Limiting temperature	-40 ... +70 °C
Mating cycles	≥500

Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	RAL 7032 (pebble grey)



Pushing Performance

Material properties

Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	No
California Proposition 65 substances	Yes
California Proposition 65 substances	Nickel

Specifications and approvals

Specifications	EN 60664-1
	IEC 61984
UL / CSA	UL 1977 ECBT2.E235076
	CSA-C22.2 No. 182.3 ECBT8.E235076

Commercial data

Packaging size	1
Net weight	8.22 g
Country of origin	Germany
European customs tariff number	85389099
eCl@ss	27440205 Contact insert for industrial connectors

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

09150033001