

LP-ADAPTER Han DD

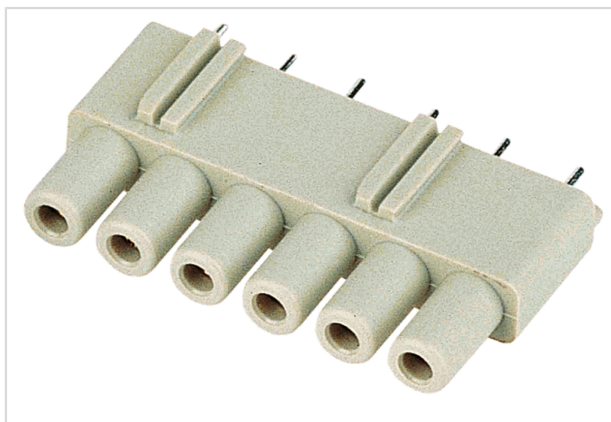


Image is for illustration purposes only. Please refer to product description.

Part number	09 16 000 9905
Specification	LP-ADAPTER Han DD
HARTING eCatalogue	https://b2b.harting.com/09160009905

Identification

Category	Accessories
Type of accessory	PCB adapter
Description of the accessory	In the Han DD [®] crimp insert
	In the Han DD [®] module
	In the Han [®] DDD module (different electrical data: 7.5 A 160 V 2.5 kV 3)

Version

Gender	Male
	Female
Details	for PCB's up to 1.6 mm

Technical characteristics

Rated current	7.5 A
Rated voltage	250 V
Rated impulse voltage	4 kV
Pollution degree	3
Limiting temperature	-40 ... +125 °C

Material properties

Material (insert)	Polyamide (PA)
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption
China RoHS	50



Pushing Performance

Material properties

REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	Yes
REACH SVHC substances	Lead
California Proposition 65 substances	Yes
California Proposition 65 substances	Nickel
	Lead

Specifications and approvals

UL / CSA	UL 1977 ECBT2.E235076
	CSA-C22.2 No. 182.3 ECBT8.E235076

Commercial data

Packaging size	10
Net weight	2.6 g
Country of origin	Germany
European customs tariff number	85366990
eCl@ss	27460201 PCB connector (board connector)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

09160009905