

## SEK CAB FLAT STD HF AWG28/7 06P 30,48m

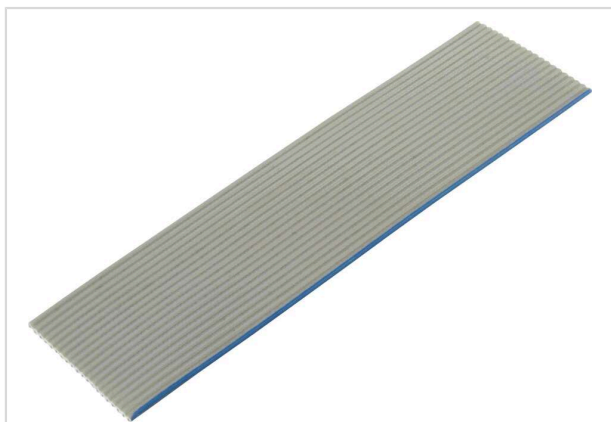


Image is for illustration purposes only. Please refer to product description.

Part number	09 18 006 7001 900
Specification	SEK CAB FLAT STD HF AWG28/7 06P 30,48m
HARTING eCatalogue	<a href="https://b2b.harting.com/09180067001900">https://b2b.harting.com/09180067001900</a>

### Identification

Category	System cabling
Element	Bulk cables
Specification	Not assembled
Type of cable	Copper cable (flat)

### Version

Cable length	30.48 m
Number of cores	6
Core structure	AWG 28/7

### Technical characteristics

Impedance	110 $\Omega$
Limiting temperature	-40 ... +105 °C unmoved -20 ... +105 °C moved

### Material properties

Material (cable)	Non-halogenated
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained



Pushing Performance  
Since 1945

Material properties

California Proposition 65 substances	Not contained
--------------------------------------	---------------

Specifications and approvals

Specifications	UL 1581
	UL 758
Approvals	CE

Commercial data

Packaging size	1
Net weight	589 g
Net weight	11 g/m
Country of origin	USA
European customs tariff number	85444993
GTIN	5713140024199
ETIM	EC003249
eCl@ss	27061801 Data and communication cable (copper)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09180067001900](#)