



Pushing Performance
Since 1945

SEK CAB FLAT STD HF AWG28/7 09P 30,48m

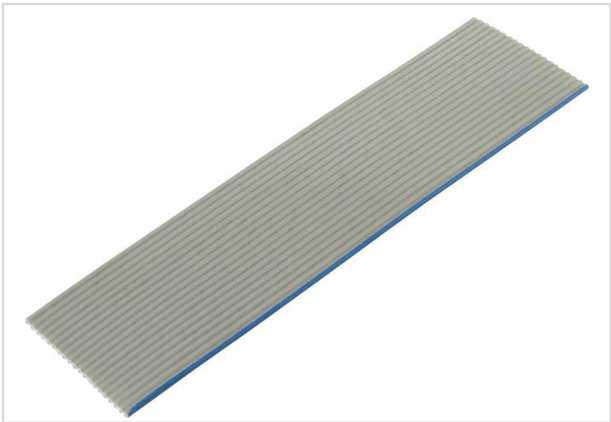


Image is for illustration purposes only. Please refer to product description.

Part number	09 18 009 7001 900
Specification	SEK CAB FLAT STD HF AWG28/7 09P 30,48m
HARTING eCatalogue	https://b2b.harting.com/09180097001900

Identification

Category	System cabling
Element	Bulk cables
Specification	Not assembled
Type of cable	Copper cable (flat)

Version

Cable length	30.48 m
Number of cores	9
Core structure	AWG 28/7

Technical characteristics

Impedance	110 Ω
Limiting temperature	-40 ... +105 °C unmoved -20 ... +105 °C moved

Material properties

Material (cable)	Non-halogenated
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained



Pushing Performance
Since 1945

Material properties

California Proposition 65 substances Not contained

Specifications and approvals

Specifications	UL 1581
	UL 758
Approvals	CE

Commercial data

Packaging size	1
Net weight	520 g
Country of origin	USA
European customs tariff number	85444993
GTIN	5713140024236
ETIM	EC003249
eCl@ss	27061801 Data and communication cable (copper)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09180097001900](#)