

SEK CAB FLAT STD HF AWG28/7 50P 30,48m

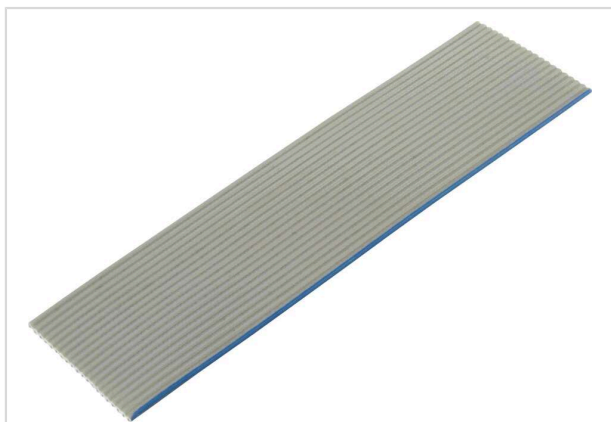


Image is for illustration purposes only. Please refer to product description.

Part number	09 18 050 7001 900
Specification	SEK CAB FLAT STD HF AWG28/7 50P 30,48m
HARTING eCatalogue	https://b2b.harting.com/09180507001900

Identification

Category	System cabling
Element	Bulk cables
Specification	Not assembled
Type of cable	Copper cable (flat)

Version

Cable length	30.48 m
Number of cores	50
Core structure	AWG 28/7

Technical characteristics

Impedance	110 Ω
Limiting temperature	-40 ... +105 °C unmoved -20 ... +105 °C moved

Material properties

Material (cable)	Non-halogenated
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained



Pushing Performance
Since 1945

Material properties

California Proposition 65 substances	Not contained
--------------------------------------	---------------

Specifications and approvals

Specifications	UL 1581
	UL 758
Approvals	CE

Commercial data

Packaging size	1
Net weight	2,948 g
Net weight	91 g/m
Country of origin	USA
European customs tariff number	85444993
GTIN	5713140025257
ETIM	EC003249
eCl@ss	27061801 Data and communication cable (copper)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09180507001900](#)