

Han 10A-HTE0-HC-for SL

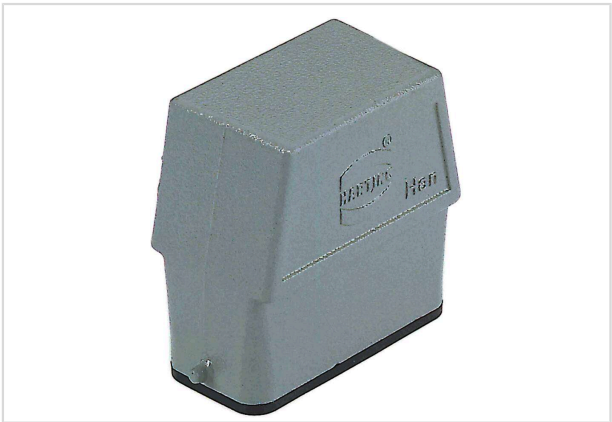


Image is for illustration purposes only. Please refer to product description.

Part number	09 20 010 0801
Specification	Han 10A-HTE0-HC-for SL
HARTING eCatalogue	https://b2b.harting.com/09200100801

Identification

Category	Hoods/Housings
Series of hoods/housings	Han A [®]
Type of hood/housing	Hood
Type	High construction

Version

Size	10 A
Version	Without cable entry
Locking type	Single locking lever
Field of application	Standard Hoods/housings for industrial applications

Technical characteristics

Limiting temperature	-40 ... +125 °C
Note on the limiting temperature	For use as a connector according to IEC 61984.
Degree of protection acc. to IEC 60529	IP65
Type rating acc. to UL 50 / UL 50E	4
	4X
	12

Material properties

Material (hood/housing)	Aluminium die-cast
Surface (hood/housing)	Powder-coated
Colour (hood/housing)	RAL 7037 (dust grey)
RoHS	compliant



Pushing Performance
Since 1945

Material properties

ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Naphthalene
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R1 (HL 1-3)
	R7 (HL 1-3)

Specifications and approvals

UL / CSA	UL 1977 ECBT2.E235076
	CSA-C22.2 No. 182.3 ECBT8.E235076
Approvals	CE
	DNV GL

Commercial data

Packaging size	1
Net weight	130 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140039346
ETIM	EC000437
eCl@ss	27440202 Shell for industrial connectors

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09200100801](#)