

Han Split Hood 16 B

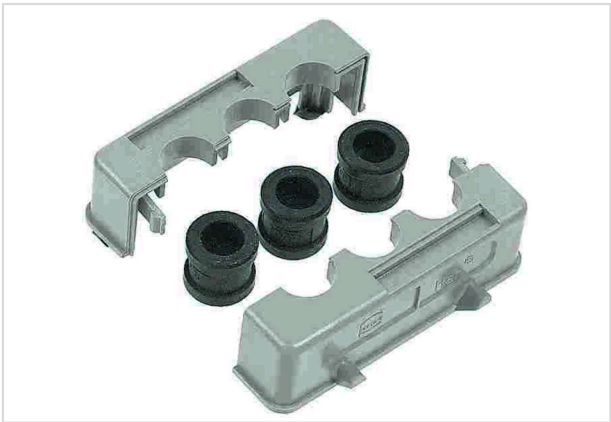


Image is for illustration purposes only. Please refer to product description.

Part number	09 30 016 0408
Specification	Han Split Hood 16 B
HARTING eCatalogue	https://b2b.harting.com/09300160408

Identification

Category	Hoods/Housings
Series of hoods/housings	Han® B
Type of hood/housing	Panel feed through housing
Type	High construction

Version

Size	16 B
Version	Top entry
Cable entry	3x Integrated
Locking type	Double locking lever
Field of application	Standard hoods/housings for industrial connectors
Details	Please order cable entry seals separately. IP54 when mounted vertically
Pack contents	2 split hood halves

Technical characteristics

Limiting temperature	-40 ... +125 °C
Note on the limiting temperature	For use as a connector according to IEC 61984.
Degree of protection acc. to IEC 60529	IP65
Type rating acc. to UL 50 / UL 50E	4
	4X
	12
Cable diameter	17.6 mm



Pushing Performance
Since 1945

Material properties

Material (hood/housing)	Polycarbonate (PC)
Colour (hood/housing)	RAL 7037 (dust grey)
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R1 (HL 1-3)
	R7 (HL 1-3)

Specifications and approvals

UL / CSA	UL 1977 ECBT2.E235076
	CSA-C22.2 No. 182.3 ECBT8.E235076
Approvals	CE

Commercial data

Packaging size	1
Net weight	42 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140045774
ETIM	EC000437
eCl@ss	27440202 Shell for industrial connectors

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09300160408](#)