

Han 10B-SCP-HBM-DL

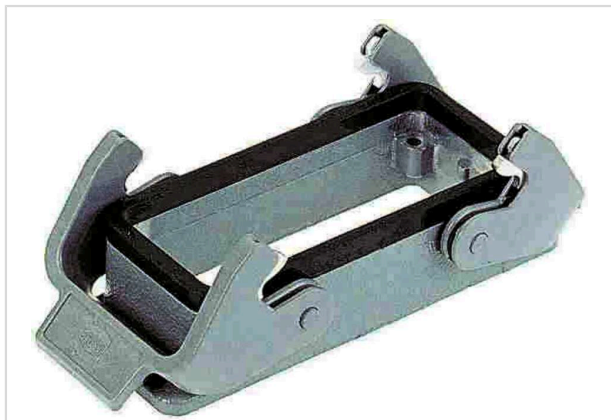


Image is for illustration purposes only. Please refer to product description.

Part number	09 30 910 0301
Specification	Han 10B-SCP-HBM-DL
HARTING eCatalogue	https://b2b.harting.com/09309100301

Identification

Category	Hoods/Housings
Series of hoods/housings	Han® B
Type of hood/housing	Bulkhead mounted housing
Description of hood/housing	Corrosion resistant
Type	Low construction

Version

Size	10 B
Locking type	Double locking lever
Han-Easy Lock®	Yes
Field of application	Standard hoods/housings for industrial connectors

Technical characteristics

Limiting temperature	-40 ... +125 °C
Note on the limiting temperature	For use as a connector according to IEC 61984.
Degree of protection acc. to IEC 60529	IP65
Type rating acc. to UL 50 / UL 50E	4
	4X
	12

Material properties

Material (hood/housing)	Aluminium die-cast
Surface (hood/housing)	Powder-coated
Colour (hood/housing)	RAL 7037 (dust grey)



Pushing Performance
Since 1945

Material properties

Material (seal)	NBR
Material (locking)	Polycarbonate (PC) Stainless steel
Colour (locking)	RAL 7037 (dust grey)
Material flammability class acc. to UL 94 (locking levers)	V-0

Specifications and approvals

Approvals	CE DNV GL
-----------	--------------

Commercial data

Packaging size	1
Country of origin	China
European customs tariff number	85366990
GTIN	5713140164529
ETIM	EC000437
eCl@ss	27440202 Shell for industrial connectors

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09309100301](#)