

Han HsB-SMC-FC-CRT-1.5 mm² / 16 AWG-Ag

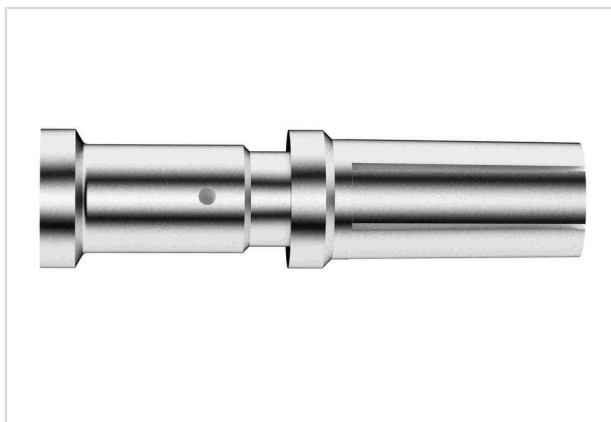


Image is for illustration purposes only. Please refer to product description.

| | |
|--------------------|---|
| Part number | 09 31 000 6204 |
| Specification | Han HsB-SMC-FC-CRT-1.5 mm ² / 16 AWG-Ag |
| HARTING eCatalogue | https://b2b.harting.com/09310006204 |

Identification

| | |
|-----------------|----------------------|
| Category | Contacts |
| Series | Han [®] HsB |
| Type of contact | Crimp contact |

Version

| | |
|-----------------------|-----------------|
| Gender | Female |
| Manufacturing process | Turned contacts |

Technical characteristics

| | |
|-------------------------|---------------------|
| Conductor cross-section | 1.5 mm ² |
| Conductor cross-section | AWG 16 |
| Rated current | ≤35 A |
| Contact resistance | ≤1 mΩ |
| Stripping length | 9.5 mm |

Material properties

| | |
|-----------------------------|--|
| Material (contacts) | Copper alloy |
| Surface (contacts) | Silver plated |
| RoHS | compliant with exemption |
| RoHS exemptions | 6(c): Copper alloy containing up to 4 % lead by weight |
| ELV status | compliant with exemption |
| China RoHS | 50 |
| REACH Annex XVII substances | Not contained |



Pushing Performance
Since 1945

Material properties

| | |
|--------------------------------------|---------------|
| REACH ANNEX XIV substances | Not contained |
| REACH SVHC substances | Yes |
| REACH SVHC substances | Lead |
| California Proposition 65 substances | Yes |
| California Proposition 65 substances | Lead |

Specifications and approvals

| | |
|----------------|-------------|
| Specifications | IEC 60664-1 |
| | IEC 61984 |

Commercial data

| | |
|--------------------------------|--|
| Packaging size | 25 |
| Net weight | 2.59 g |
| Country of origin | Germany |
| European customs tariff number | 85366990 |
| GTIN | 5713140188075 |
| ETIM | EC000796 |
| eCl@ss | 27440204 Contact for industrial connectors |

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09310006204](#) [9310006204](#)