

Han-Snap Panel mounting parts

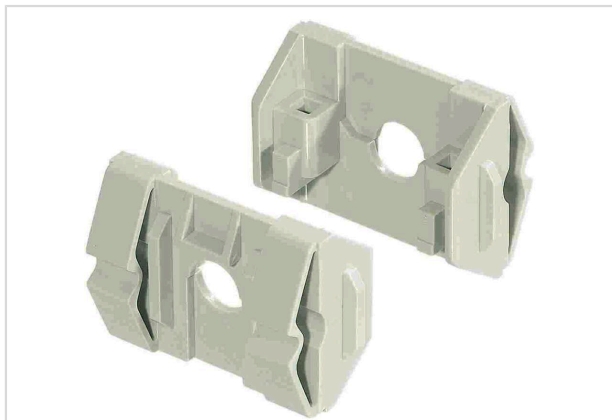


Image is for illustration purposes only. Please refer to product description.

Part number	09 33 000 9985
Specification	Han-Snap Panel mounting parts
HARTING eCatalogue	https://b2b.harting.com/09330009985

Identification

Category	Accessories
Series	Han-Snap®
Type of accessory	Panel mounting parts

Version

Details	Size 10 A / 16 A by using the corresponding adapter!
Pack contents	2 plastic panel mounting parts sufficient for one insert or terminal block connector

Technical characteristics

Tightening torque	0.8 Nm
Limiting temperature	-40 ... +125 °C
Retention force	≥250 N in the sheet-metal cut out

Material properties

Material (accessories)	Polycarbonate (PC)
Colour (accessories)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Yes



Pushing Performance
Since 1945

Material properties

REACH SVHC substances	Potassium 1,1,2,2,3,3,4,4,4-nonafluorobutane-1-sulphonate
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R22 (HL 1-3) R23 (HL 1-3)

Specifications and approvals

Specifications	IEC 60068-2-6 Vibration (sinusoidal) IEC 60068-2-27 Shock
----------------	--

Commercial data

Packaging size	10
Net weight	10 g
Country of origin	Germany
European customs tariff number	85366990
GTIN	5713140050631
ETIM	EC002939
eCl@ss	27440392 Connector (accessories)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09330009985](#)