

Han U Protect Cover Die Cast for Hood PG

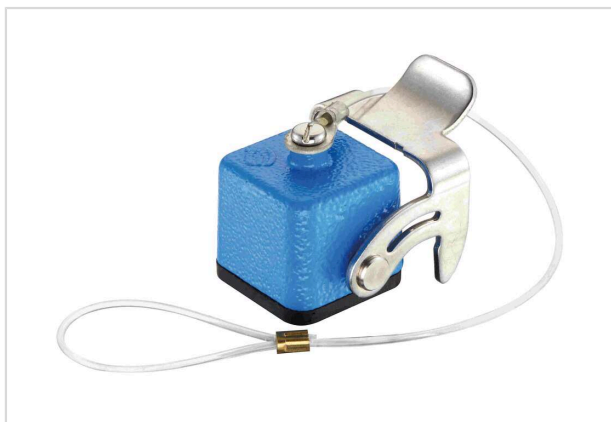


Image is for illustration purposes only. Please refer to product description.

Part number	09 36 003 5401
Specification	Han U Protect Cover Die Cast for Hood PG
HARTING eCatalogue	https://b2b.harting.com/09360035401

Identification

Category	Accessories
Series of hoods/housings	Han [®] Ex
Type of accessory	Protection cover
Description of the accessory	for hoods
	Metal
	With fixing cord
	With seal

Version

Size	3 A
Locking type	Single locking lever
Details	for mounted female insert
Details	ATTENTION! Only to be used with Han [®] Ex hoods and housings!

Technical characteristics

Limiting temperature	-20 ... +40 °C
Degree of protection acc. to IEC 60529	IP65 With cable gland

Material properties

Material (hood/housing)	Zinc die-cast
Surface (hood/housing)	Powder-coated
Colour (hood/housing)	RAL 5015 (sky blue)
Material (seal)	NBR
Material (locking)	Steel



Pushing Performance
Since 1945

Material properties

Surface (locking)	Zinc plated
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead
	Nickel
	Naphthalene

Commercial data

Packaging size	10
Net weight	29 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140054738
ETIM	EC002314
eCl@ss	27440208 Cap for industrial connectors

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09360035401](#)