

Han 3HPR Hood cover,screw lock,chrome pl

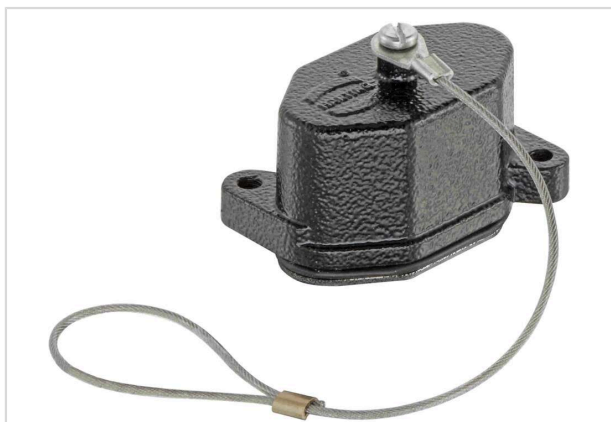


Image is for illustration purposes only. Please refer to product description.

Part number	09 40 003 5414
Specification	Han 3HPR Hood cover,screw lock,chrome pl
HARTING eCatalogue	https://b2b.harting.com/09400035414

Identification

Category	Accessories
Series of hoods/housings	Han [®] HPR
Type of accessory	Protection cover
Description of the accessory	for hoods With fixing cord

Version

Size	3 A
Locking type	Screw locking

Technical characteristics

Tightening torque (screw locking)	2 Nm
Limiting temperature	-40 ... +125 °C
Degree of protection acc. to IEC 60529	IP65 IP68 IP69 / IPX9K acc. to ISO 20653
Type rating acc. to UL 50 / UL 50E	4 4X 12

Material properties

Material (hood/housing)	Zinc die-cast
Surface (hood/housing)	Black chrome coating
Colour (hood/housing)	RAL 9005 (jet black)
Material (seal)	NBR



Pushing Performance
Since 1945

Material properties

RoHS	not compliant
ELV status	not compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead
	Nickel
	Naphthalene

Specifications and approvals

UL / CSA	UL 1977 ECBT2.E235076
	CSA-C22.2 No. 182.3 ECBT8.E235076
Approvals	DNV GL

Commercial data

Packaging size	10
Net weight	44.5 g
Country of origin	China
European customs tariff number	85389099
GTIN	5713140191990
ETIM	EC002314
eCl@ss	27440208 Cap for industrial connectors

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09400035414](#) [9400035414](#)