



Pushing Performance
Since 1945

Han3A RJ45 PFT adapter

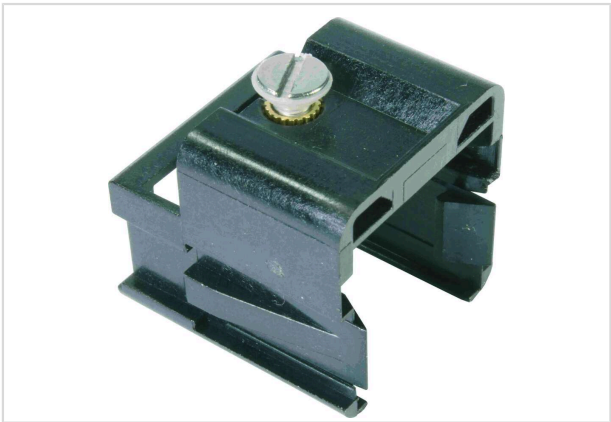


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 515 0020
Specification	Han3A RJ45 PFT adapter
HARTING eCatalogue	https://b2b.harting.com/09455150020

Identification

Category	Connectors
Series	RJ45
Element	Adapter
Specification	for fixing of RJ45 jacks

Version

Size	3 A
Shielding	Unshielded
PCB fixing	With snap-in clip

Technical characteristics

Limiting temperature	-40 ... +70 °C
Mating cycles	≥500

Material properties

Material (hood/housing)	Polycarbonate (PC)
Colour (hood/housing)	Black
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained



Pushing Performance
Since 1945

Material properties

REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead
	Nickel

Specifications and approvals

Specifications	EN 45545-2
Approvals	DNV GL

Commercial data

Packaging size	100
Net weight	3.04 g
Country of origin	Romania
European customs tariff number	85389099
GTIN	5713140060920
ETIM	EC002310
eCl@ss	27440210 Fixing element for industrial connectors

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09455150020](#)