

## HPP V4 USB 2.0 B, PFT insert



Image is for illustration purposes only. Please refer to product description.

### Identification

Category	Connectors
Series	HARTING PushPull (V4)
Identification	USB
Element	Female
Specification	USB 2.0 type B Angled

### Version

Shielding	Fully shielded, 360° shielding contact
Number of contacts	4

### Technical characteristics

Limiting temperature	-40 ... +70 °C
Mating cycles	≥750

### Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes

## Material properties

California Proposition 65 substances	Antimony trioxide Lead Naphthalene
--------------------------------------	--



## Specifications and approvals

Specifications	IEC 61076-3-106 Variant 4 (V4)
Approvals	DNV GL

## Commercial data

Packaging size	1
Net weight	5.3 g
Country of origin	Germany
European customs tariff number	85366930
GTIN	5713140061002
ETIM	EC000438
eCl@ss	27440205 Contact insert for industrial connectors

## Mounting instruction

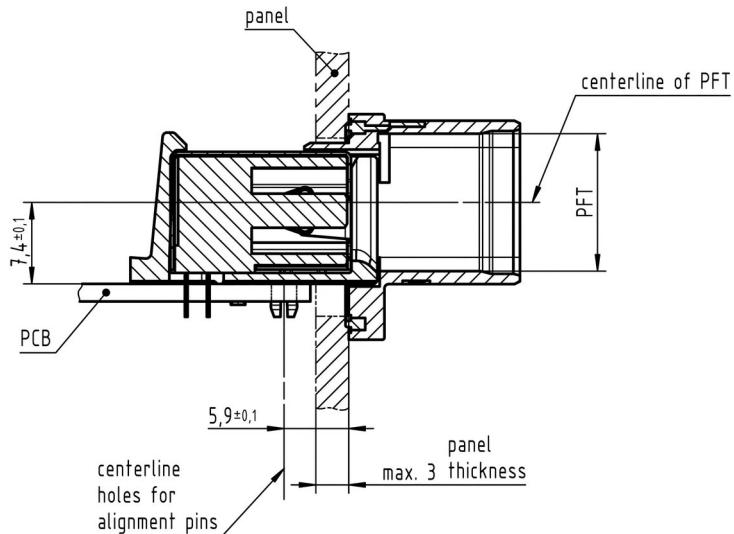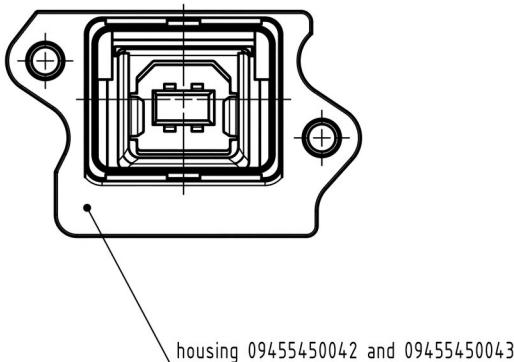

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09455411900](#)