

## Bulkhead USB Type C HIFF

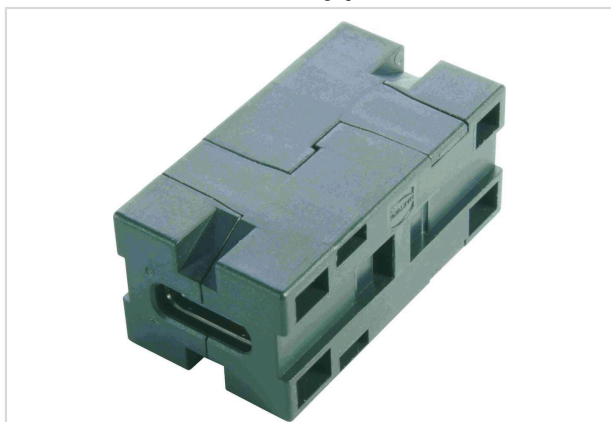


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 545 1905
Specification	Bulkhead USB Type C HIFF
HARTING eCatalogue	<a href="https://b2b.harting.com/09455451905">https://b2b.harting.com/09455451905</a>

### Identification

Category	Connectors
Series	har-port
Element	Service interfaces
Features	supports USB Power Delivery (USB-PD)

### Version

Connection type	Type C jack - type C jack
Number of contacts	24
Fixing	Screwable in cover plates

### Technical characteristics

Rated current	5 A
Rated voltage	20 V
Ambient temperature	-40 ... +85 °C
Mating cycles	≥10,000
Degree of protection acc. to IEC 60529	IP20
Vibration resistance	Category 1B acc. to IEC 61373
Shock resistance	Category 1B acc. to IEC 61373

### Material properties

Material (hood/housing)	Polyamide (PA)
Colour (hood/housing)	Black
RoHS	compliant



**Pushing Performance**  
Since 1945

## Material properties

ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Nickel
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R26

## Commercial data

Packaging size	1
Net weight	6.93 g
Country of origin	Germany
European customs tariff number	85366990
eCl@ss	27060304 Appliance cord (data cable)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

09455451905