



Pushing Performance  
Since 1945

# RJI RJ45 jack Cat.5 SMT angled T&R (130)

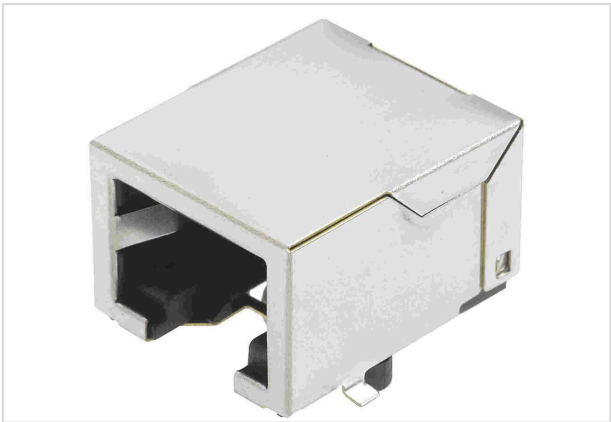


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 551 1110
Specification	RJI RJ45 jack Cat.5 SMT angled T&R (130)
HARTING eCatalogue	<a href="https://b2b.harting.com/09455511110">https://b2b.harting.com/09455511110</a>

## Identification

Category	Connectors
Series	HARTING RJ Industrial®
Element	Female
Specification	RJ45 Angled

## Version

Termination method	Reflow soldering termination (SMT)
Shielding	Fully shielded, 360° shielding contact
Number of contacts	8
Pack contents	Tape & reel

## Technical characteristics

Rated current	1.5 A
Transmission characteristics	Cat. 5 Class D up to 100 MHz
Data rate	10 Mbit/s
	100 Mbit/s
	1 Gbit/s
	2.5 Gbit/s
Limiting temperature	-40 ... +85 °C
Mating cycles	≥750
Degree of protection acc. to IEC 60529	IP20



**Pushing Performance**  
Since 1945

## Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead Nickel

## Specifications and approvals

UL / CSA	UL 1977 DUXR2.E254191 CSA-C22.2 No. 182.4, No. 233-09 DUXR8.E254191
Approvals	DNV GL

## Commercial data

Packaging size	130
Net weight	1 g
Country of origin	Taiwan
European customs tariff number	85366990
GTIN	5713140061538
ETIM	EC002637
eCl@ss	27460201 PCB connector (board connector)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09455511110](#)