

RJ45 Ca. AWG 26/7, stra. PUR, IP20; 3,0m, CAT6

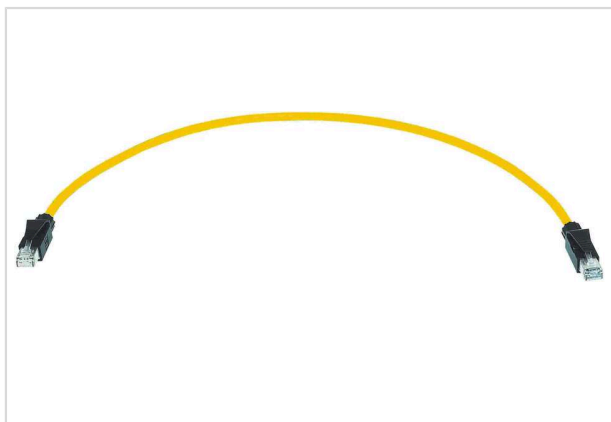


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 751 1565
Specification	RJ45 Ca. AWG 26/7, stra. PUR, IP20; 3,0m, CAT6
HARTING eCatalogue	https://b2b.harting.com/09457511565

Identification

Category	System cabling
Series	RJ45
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	HARTING RJ Industrial®
Connector 2	HARTING RJ Industrial®
Type of cable	Copper cable (round)

Version

Cable length	3 m
Number of cores	8
Core structure	4x 2x AWG 26/7

Technical characteristics

Transmission characteristics	Cat. 6A Class E _A up to 500 MHz
Data rate	10 Mbit/s
	100 Mbit/s
	1 Gbit/s
	2.5 Gbit/s
	5 Gbit/s
	10 Gbit/s

Material properties

Material (cable)	PUR (polyurethane)
------------------	--------------------



Pushing Performance
Since 1945

Material properties

Colour (cable)	Yellow
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

Commercial data

Packaging size	1
Net weight	178.82 g
Country of origin	Romania
European customs tariff number	85444290
GTIN	5713140255401
eCl@ss	27060308 Patch cord copper (data cable)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[09457511565](#)