



Pushing Performance
Since 1945

Han 10HvE-gg-M32

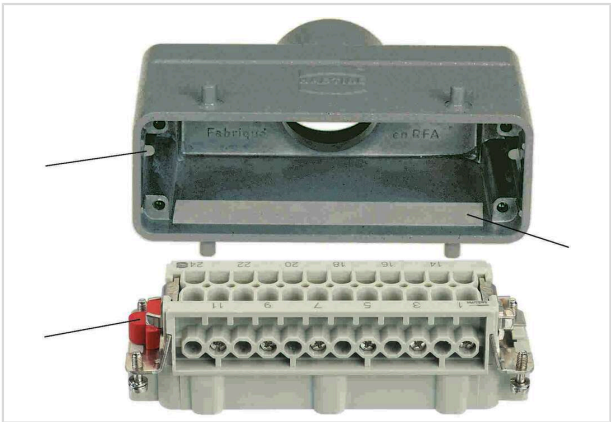


Image is for illustration purposes only. Please refer to product description.

Part number	19 34 010 0422
Specification	Han 10HvE-gg-M32
HARTING eCatalogue	https://b2b.harting.com/19340100422

Identification

Category	Hoods/Housings
Series of hoods/housings	Han Hv E®
Type of hood/housing	Hood
Type	Low construction

Version

Size	24 B
Version	Top entry
Cable entry	1x M32
Locking type	Double locking lever
Field of application	Special hoods/housings for Han Hv E® screw terminal

Technical characteristics

Limiting temperature	-40 ... +125 °C
Note on the limiting temperature	For use as a connector according to IEC 61984.
Degree of protection acc. to IEC 60529	IP65
Type rating acc. to UL 50 / UL 50E	4
	4X
	12

Material properties

Material (hood/housing)	Aluminium die-cast
Surface (hood/housing)	Powder-coated
Colour (hood/housing)	RAL 7037 (dust grey)



Pushing Performance
Since 1945

Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes

Specifications and approvals

Approvals	CE DNV GL
-----------	--------------

Commercial data

Packaging size	1
Net weight	211.9 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140128248
ETIM	EC000437
eCl@ss	27440202 Shell for industrial connectors

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[19340100422](#)