

## Han INOX 3A Cover for Female in Housing

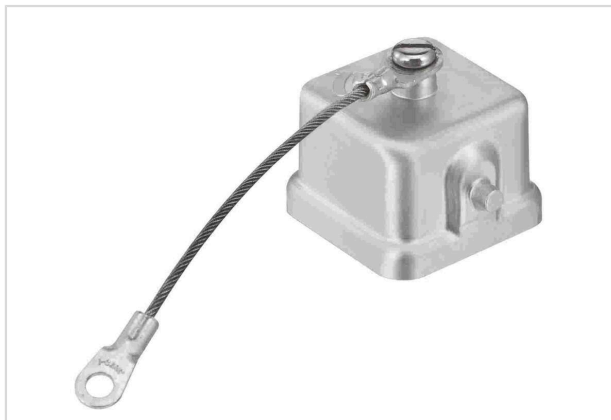


Image is for illustration purposes only. Please refer to product description.

Part number	19 44 003 5425
Specification	Han INOX 3A Cover for Female in Housing
HARTING eCatalogue	<a href="https://b2b.harting.com/19440035425">https://b2b.harting.com/19440035425</a>

### Identification

Category	Accessories
Series of hoods/housings	Han-INOX®
Type of accessory	Protection cover
Description of the accessory	for bulkhead mounted housings
	for surface mounted housings
	for cable to cable housing
	Metal
	With fixing cord (cable shoe)

### Version

Size	3 A
Locking type	Single locking lever
Details	for mounted female insert or for mounted Han-Brid® insert

### Technical characteristics

Limiting temperature	-40 ... +125 °C
Degree of protection acc. to IEC 60529	IP65
	IP67
Type rating acc. to UL 50 / UL 50E	4
	4X
	12

### Material properties

Material (seal)	FPM
RoHS	compliant



**Pushing Performance**  
 Since 1945

## Material properties

ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead
	Nickel
	Naphthalene

## Specifications and approvals

UL / CSA	UL 1977 ECBT2.E235076
	CSA-C22.2 No. 182.3 ECBT8.E235076
Approvals	DNV GL

## Commercial data

Packaging size	1
Net weight	30 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140132030
ETIM	EC002314
eCl@ss	27440208 Cap for industrial connectors

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[19440035425](#)