

M12 A-coded st fem unshielded 4P PUR 30m

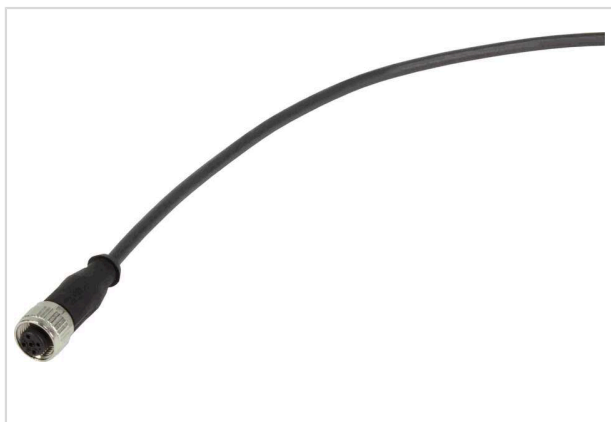


Image is for illustration purposes only. Please refer to product description.

Part number	21 34 850 0491 300
Specification	M12 A-coded st fem unshielded 4P PUR 30m
HARTING eCatalogue	https://b2b.harting.com/21348500491300

Identification

Category	System cabling
Series	Circular connectors M12
Element	Cable assemblies
Specification	Pre-assembled on one side
Connector 1	M12 A-coding Female Straight
Type of cable	Copper cable (round)

Version

Cable length	30 m
Number of cores	4
Core structure	4x 0.34 mm ²
Coding	A-coding

Material properties

Material (cable)	PUR (polyurethane)
Colour (cable)	Black
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption
China RoHS	50
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained



Pushing Performance
 Since 1945

Material properties

REACH SVHC substances	Yes
REACH SVHC substances	Lead
ECHA SCIP number	760691ac-b4d2-427c-9996-5886190b813b
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead Nickel

Commercial data

Packaging size	1
Net weight	1 g
Country of origin	Czechia
European customs tariff number	85444290
GTIN	5713140238886
ETIM	EC001855
eCl@ss	27060311 Assembled sensor actuator-line

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[21348500491300](#)