

InduCom9 9p 2T-entry hexscrew 4-40

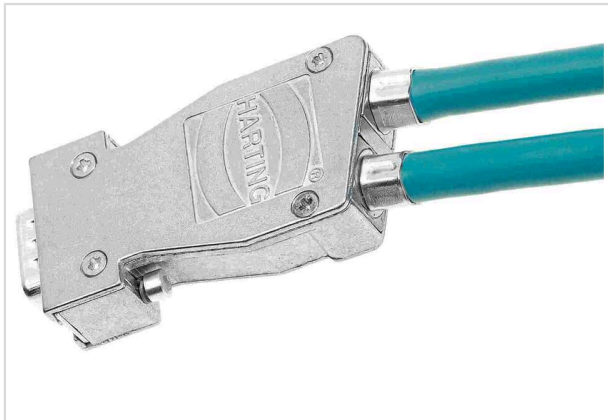


Image is for illustration purposes only. Please refer to product description.

Part number	66 67 009 0346
Specification	InduCom9 9p 2T-entry hexscrew 4-40
HARTING eCatalogue	https://b2b.harting.com/66670090346

Identification

Category	Hoods/Housings
Series of hoods/housings	D-Sub InduCom
Type of hood/housing	Shell housing
Description of hood/housing	Suitable for circuit boards

Version

Size	D-Sub 1
Version	Top entry
Cable entry	2x
Strain relief	An additional InduCom cable clamp or a crimp flange - ferrule combination is available dependant on the use of the cable.
Locking type	Hexagonal screw Thread 4-40 UNC
2 parts	Yes
Separable	Yes

Technical characteristics

Tightening torque	0.4 Nm cover screw 0.4 Nm Locking screw
Ambient temperature	-20 ... +90 °C
Degree of protection acc. to IEC 60529	IP30

Material properties

Material (hood/housing)	Zinc die-cast
Material (screw)	Brass, nickel plated



Pushing Performance
Since 1945

Material properties

Length	61.7 mm
Width	31 mm
Height	14.8 mm
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

Commercial data

Packaging size	10
Net weight	61.95 g
Country of origin	China
European customs tariff number	85389099
GTIN	5713140158658
ETIM	EC001133
eCl@ss	27440213 D-Sub hood

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[66670090346](#)