


Number of contacts

9–50

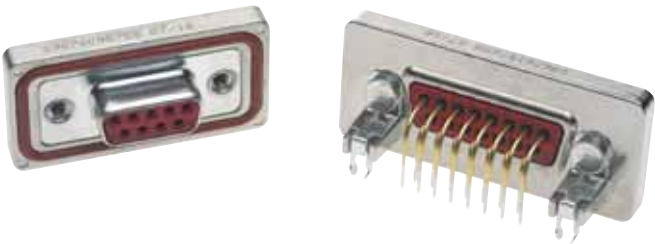

IP 67, angled turned solder pins,
with rear metal mounting plate, bracket and board lock

D-Sub

Identification	No. of contacts	Part No.	
		S4 ¹⁾	
Male connector metal shell with dimples	9	09 67 609	. 658
	15	09 67 615	. 658
	25	09 67 625	. 658
	37	09 67 637	. 658
	50	09 67 650	. 658
Please insert digit for flange thread	4-40 UNC ▶ 7		
	M3 ▶ 9		
Female connector metal shell	9	09 67 609	. 758
	15	09 67 615	. 758
	25	09 67 625	. 758
	37	09 67 637	. 758
	50	09 67 650	. 758
Please insert digit for flange thread	4-40 UNC ▶ 6		
	M3 ▶ 8		


¹⁾ S4: ≥ 0.76 µm Au (30 µinch)

D-Sub

Number of contacts

9–50

IP 67, angled turned solder pins,
with rear metal mounting plate, bracket and board lock

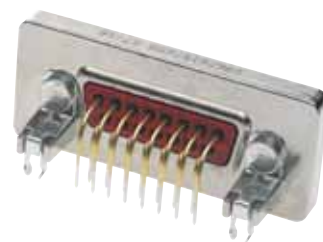


Identification

Drawing

Dimensions in mm


Male connector
9 – 50 contacts

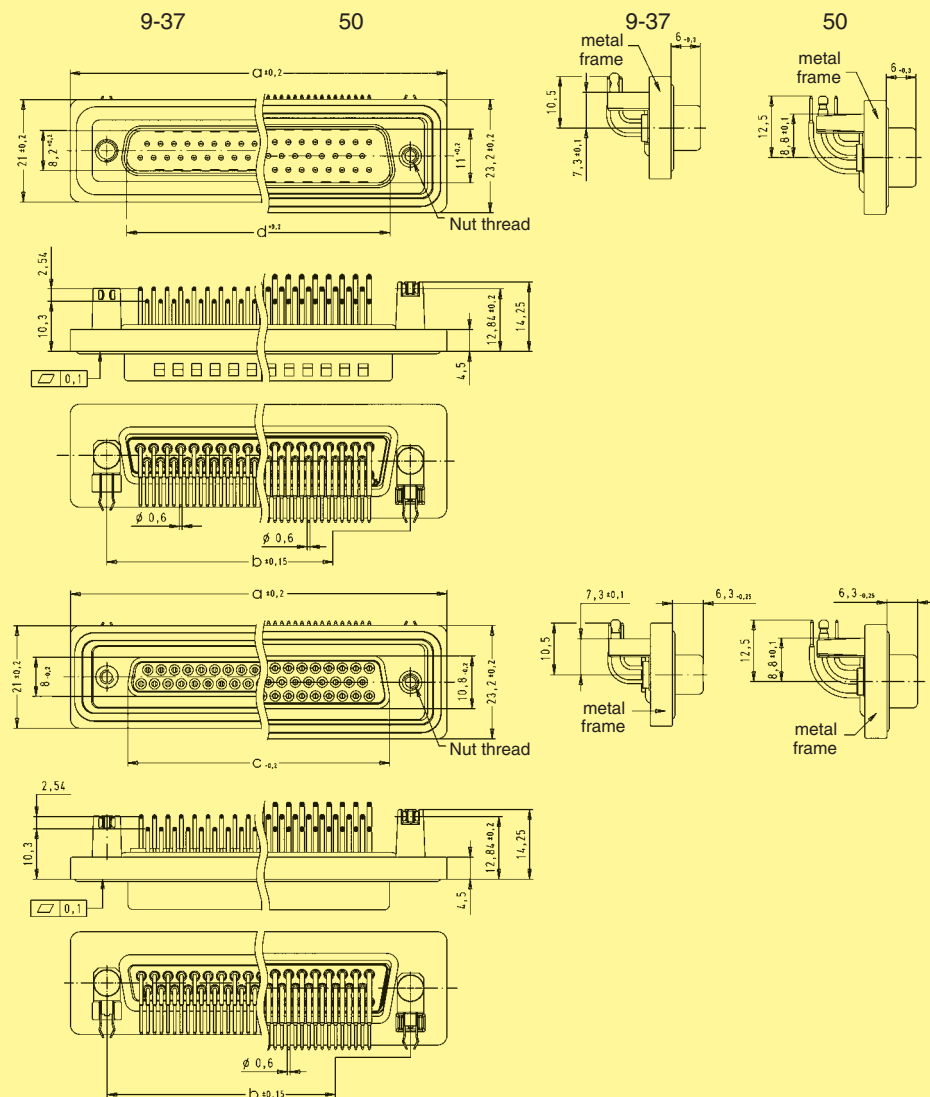

Female connector
9 – 50 contacts

	a	b	c	d	g	h
9	40.0	25.00	16.4	16.9	4 x $2.74 = 10.96$	3 x $2.74 = 8.22$
15	48.3	33.30	24.7	25.2	7 x $2.74 = 19.18$	6 x $2.74 = 16.44$
25	62.0	47.04	38.5	38.9	12 x $2.76 = 33.12$	11 x $2.76 = 30.36$
37	78.5	63.50	54.9	55.3	18 x $2.76 = 49.68$	17 x $2.76 = 46.92$
50	76.1	61.10	52.5	52.8	16 x $2.76 = 44.16$	15 x $2.76 = 41.40$

Board drillings

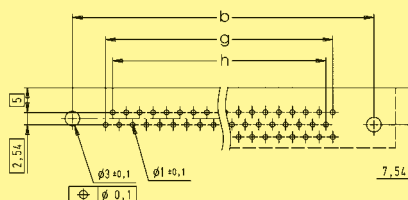

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[09676096758](#) [09676158758](#) [09676377658](#) [09676157658](#) [09676258758](#) [09676159658](#) [09676379658](#)
[09676509658](#)