

Technical Characteristics

Part Number

Han 6B Rear-Mount Kit


Hood	Side Entry
Housing	Single Lever Bulkhead
Material	Die Cast Aluminum
IP / NEMA	IP66 / 4, 4x, 12
Temp Rating	-40 to +125C
Cable Gland	M25 Metal
Cable Diameter	9-16mm / 13-18mm
Insert	Han 6E, 6+GND
Screw Terminals	18-14AWG
Wire Strip Length	7.5mm
Mating Cycles	>500
Flammability	V-0

Electrical Characteristics

Rated Current	16amps
Rated Voltage	600V
Rated Impulse Voltage	6kV


73 10 100 0005

UL508

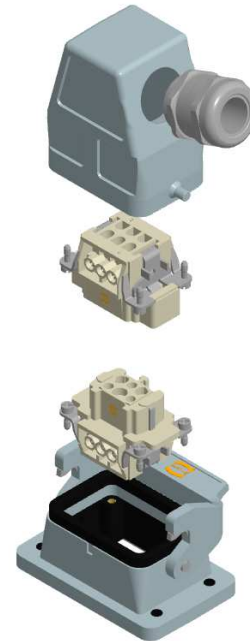


Drawings and Assembly Information

Dimensions in mm

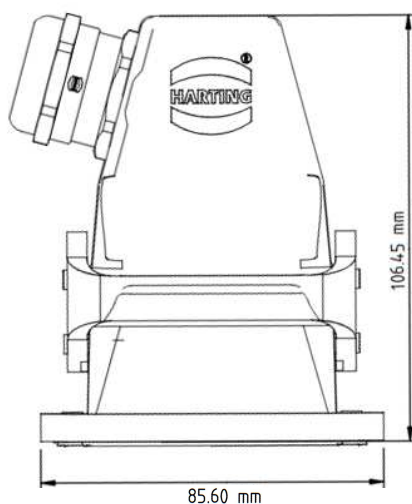

panel cut out

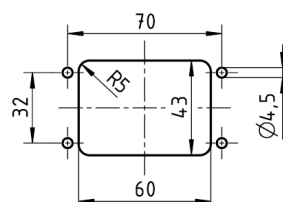

Tooling and Torque Values

Type	Tool	Torque (Nm)
Terminal Screws (M3)	PH1 or Slotted 0.6 x 3.5	0.50
Fixing Screw (M3)	PH2 or Slotted 0.6 x 3.5	0.50
Mounting Screws (M4 recommended)	-	0.8...1.0
Cable Gland (M25)	SW 30	12

Kit Contents

Male Insert	09 33 006 2601
Female insert	09 33 006 2701
Housing	09 30 006 0391
Hood	19 30 006 0546
Cable Gland	19 00 000 5091

For further information, please reach out to
techsupportUS@HARTING.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[73101000005](#)