




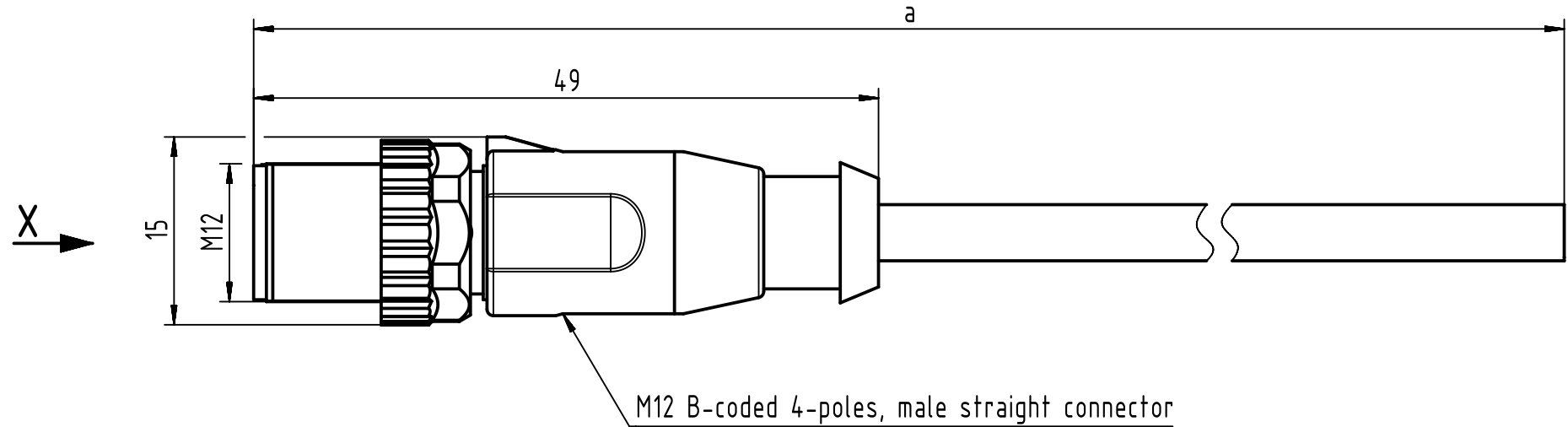

M12 B-coded 4-poles, male straight connector

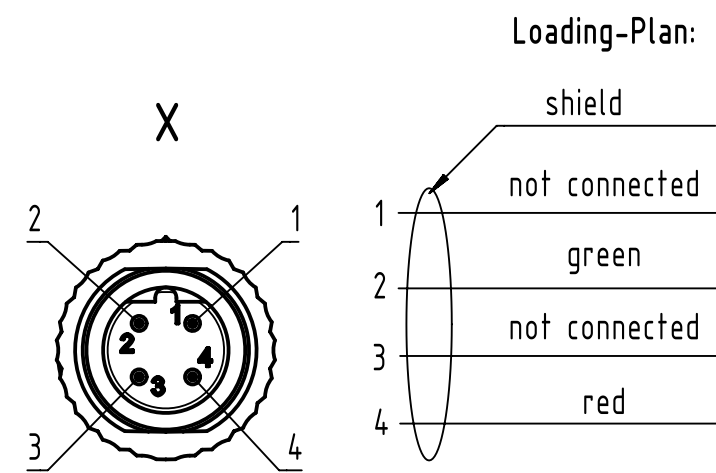

- Protection level: IP67
- Temperature range: -30°C ... +60°C

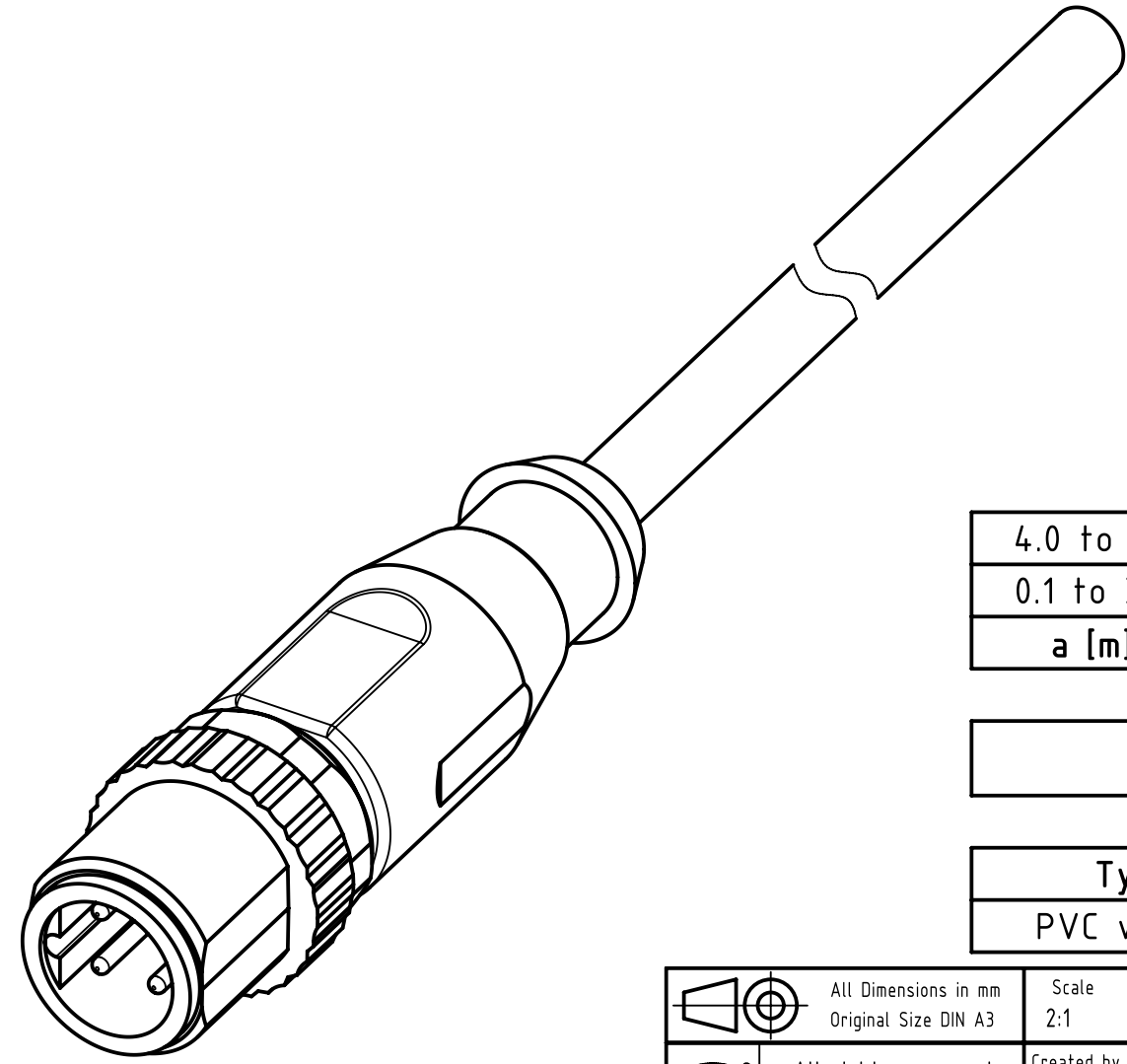

length in "1m" step	40	XXX=400
	39	XXX=390
	.	.
	12	XXX=120
	11	XXX=110
length in "0.1m" step	10	XXX=100
	9.9	XXX=099
	9.8	XXX=098
	.	.
	0.4	XXX=004
	0.3	XXX=003
	0.2	XXX=002
	0.1	XXX=001
Step	a [m]	XXX

4.0 to 40	+1%
0.1 to 3.9	+0.04
a [m]	Tolerance

Part no.	213488004XXXXX
----------	----------------

Type of cable	XX
PVC violet, 2xAWG22	XX=86

All rights reserved
Department EC PD - RO
HARTING Electronics GmbH
D-32339 Espelkamp

All Dimensions in mm
Original Size DIN A3

Scale
2:1

Free size tol.

Created by
TOMUTA

Inspected by
AVRAM

Standardisation
KOHLER

Date
2014-07-16

State
Final Release

Title
M12 B-coded Cable Assembly

Type
TB

Number
213488004XXXXX

Doc-Key / ECM-Nr.
100579378/UGD/009/A
500000077557

Rev.
A

Page
1/1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[21348800486075](#) [21348800486100](#) [21348800486020](#) [21348800486005](#) [21348800486015](#)