



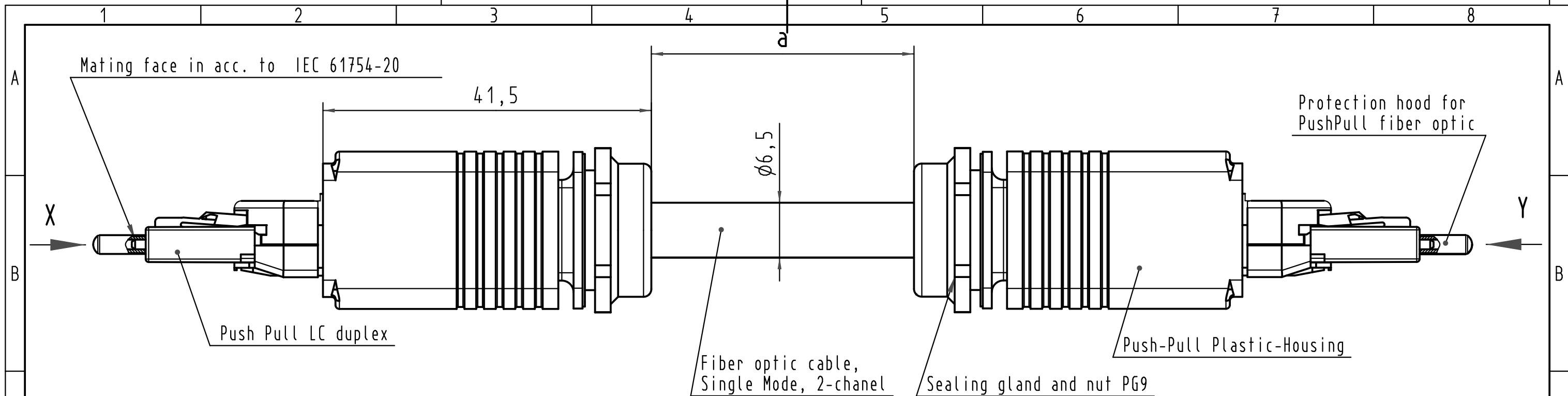


X
(without protection hood)

Loading-Plan

Y
(without protection hood)

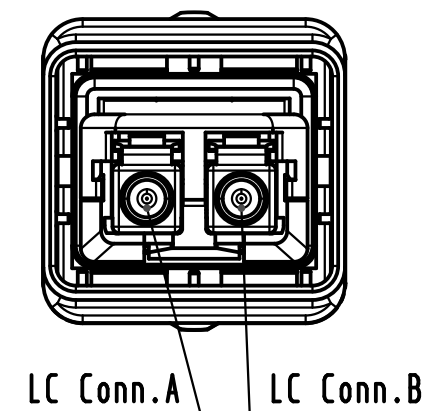

A — blue — B
B — orange — A

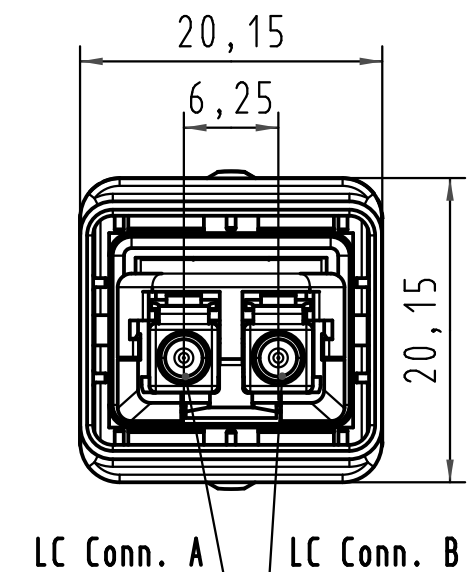

-Protection level: IP67/65
-Temperature range: -40°C ...+70°C

9	High strength fiber optic breakout cable Single Mode	33 58 211 300 0002	300 m
8	High strength fiber optic breakout cable Single Mode	33 58 211 100 0002	100 m
7	High strength fiber optic breakout cable Single Mode	33 58 211 060 0002	60 m
6	High strength fiber optic breakout cable Single Mode	33 58 211 050 0002	50 m
5	High strength fiber optic breakout cable Single Mode	33 58 211 040 0002	40 m
4	High strength fiber optic breakout cable Single Mode	33 58 211 020 0002	20 m
3	High strength fiber optic breakout cable Single Mode	33 58 211 010 0002	10 m
2	High strength fiber optic breakout cable Single Mode	33 58 211 005 0002	5 m
1	High strength fiber optic breakout cable Single Mode	33 58 211 001 0002	1 m
Cont No.	Type of cable	Part-No.	Dim. a

All Dimensions in mm Original Size DIN A 3			Techn. Character.			Nicht tolerierte Maß/Free size tolerances	
				Dat.	Name	2:1	PushPull fiber optic assembly 2xPushPull LC DUPLEX, plastic Single Mode
			Detail.	20.08.08	MR		
			Insp.	20.08.08	RA		
			Stand.				
DRS06A	21.05.09	MS				HARTING Electronics GmbH & Co. KG D-32339 ESPELKAMP	TB 33 58 211 xxx 0002
EC00166	17.02.09	MR					
35590	13.01.09	MR					
35014							
Mod.	Dat.	Name					

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[HARTING:](#)

[33582113000002](#)