

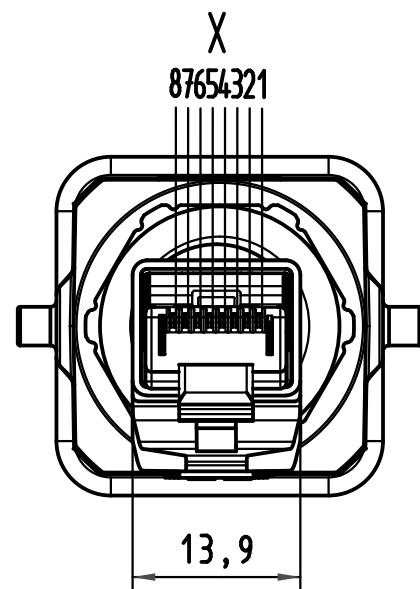


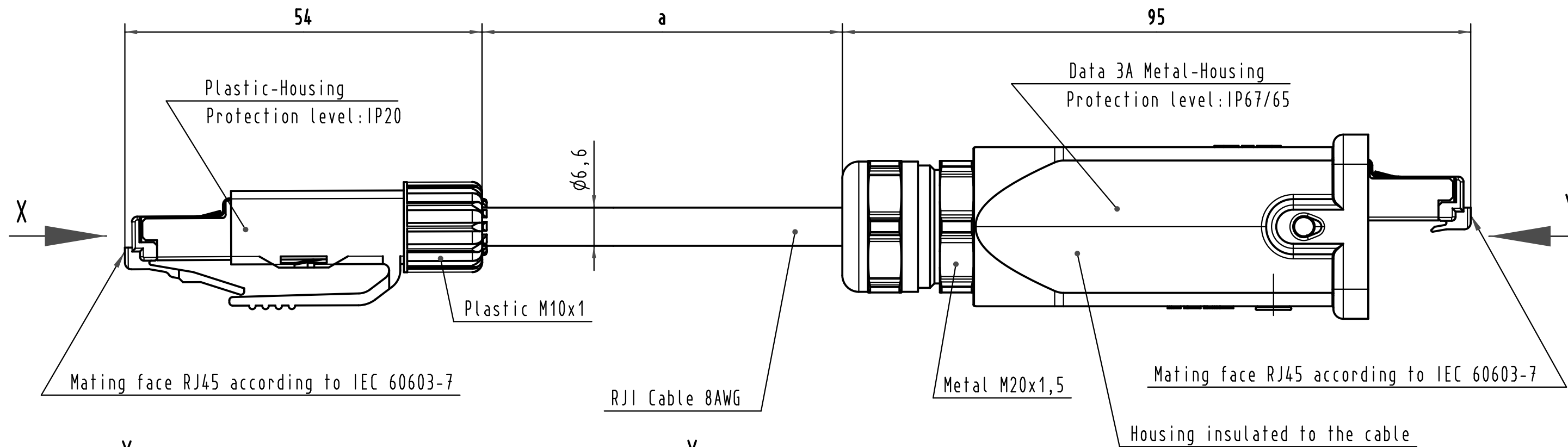


Shield

1	White(green)	1
2	Green	2
3	White(orange)	3
4	Blue	4
5	White(blue)	5
6	Orange	6
7	White(brown)	7
8	Brown	8

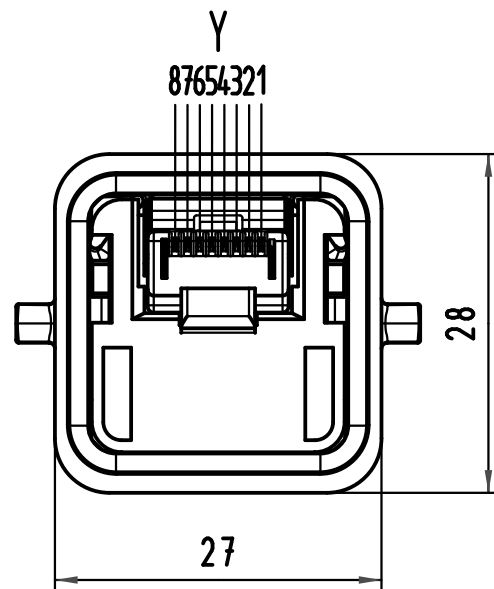

Transmission properties in accordance with ISO/IEC 11801:2002: Class E
 Temperature range: -20°C ...+60°C
 for assembly with cable PUR, CAT7
 -10°C ...+70°C
 for assembly with cable PUR and PVC, CAT6

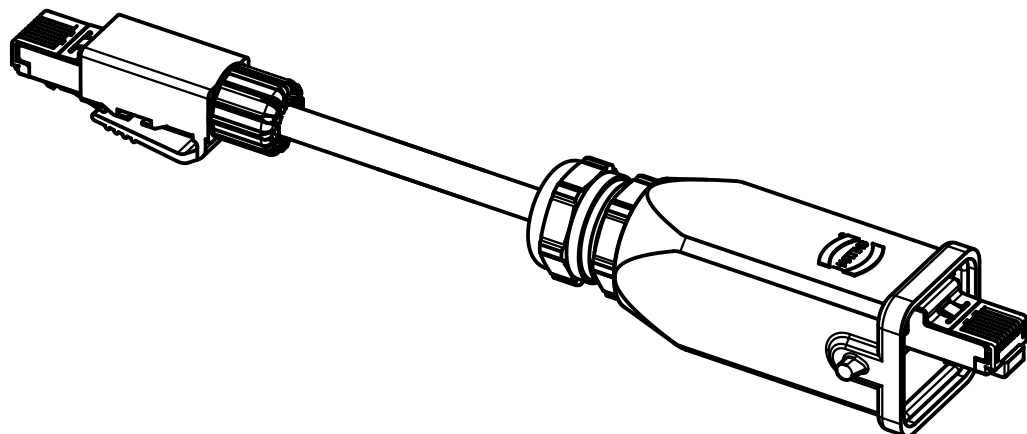

All Dimensions in mm Original Size DIN A 3			Techn. Character. techn.Character			Nicht tolerierte Maße/Free size tolerances	
				Dat.	Name	RJ45 Cord IP20+Metal-Data3A, 2xRJ45, 8AWG, stranded	Blatt/ page 1/2
			Detail.	20.11.07	MR		
			Insp.	20.11.07	RA		
			Stand.				
DRS484A	24.03.09	MS	HARTING Electronics GmbH & Co. KG D-32339 ESPELKAMP			TB 09 45 70x xxxx	Sub. Sub
35039	06.11.08	MS					
34512							
Mod.	Dat.	Name					

Alle Rechte vorbehalten/ All rights reserved

1				2				3				4				5				6				7				8			
A				Cont-No.	Part-No.				Type of cable				Dim. a[m]																		
				1	09 45 700 2501				8AWG 26/7 stranded, PUR, CAT7A				0.5 m																		
				2	09 45 700 2502				8AWG 26/7 stranded, PUR, CAT7A				1 m																		
				3	09 45 700 2503				8AWG 26/7 stranded, PUR, CAT7A				1.5 m																		
				4	09 45 700 2504				8AWG 26/7 stranded, PUR, CAT7A				2 m																		
				5	09 45 700 2505				8AWG 26/7 stranded, PUR, CAT7A				3 m																		
				6	09 45 700 2506				8AWG 26/7 stranded, PUR, CAT7A				4 m																		
				7	09 45 700 2507				8AWG 26/7 stranded, PUR, CAT7A				5 m																		
				8	09 45 700 2508				8AWG 26/7 stranded, PUR, CAT7A				6 m																		
				9	09 45 700 2509				8AWG 26/7 stranded, PUR, CAT7A				7 m																		
B				10	09 45 700 2510				8AWG 26/7 stranded, PUR, CAT7A				8 m																		
				11	09 45 700 2511				8AWG 26/7 stranded, PUR, CAT7A				9 m																		
				12	09 45 700 2512				8AWG 26/7 stranded, PUR, CAT7A				10 m																		
				13	09 45 700 2513				8AWG 26/7 stranded, PUR, CAT7A				15 m																		
				14	09 45 700 2514				8AWG 26/7 stranded, PUR, CAT7A				20 m																		
				15	09 45 701 1562				8AWG 28/7 stranded, PVC, CAT6				0.5 m																		
				16	09 45 701 1563				8AWG 28/7 stranded, PVC, CAT6				1 m																		
				17	09 45 701 1564				8AWG 28/7 stranded, PVC, CAT6				1.5 m																		
				18	09 45 701 1565				8AWG 28/7 stranded, PVC, CAT6				2 m																		
				19	09 45 701 1566				8AWG 28/7 stranded, PVC, CAT6				3 m																		
C				20	09 45 701 1567				8AWG 28/7 stranded, PVC, CAT6				4 m																		
				21	09 45 701 1568				8AWG 28/7 stranded, PVC, CAT6				5 m																		
				22	09 45 701 1569				8AWG 28/7 stranded, PVC, CAT6				6 m																		
				23	09 45 701 1570				8AWG 28/7 stranded, PVC, CAT6				7 m																		
				24	09 45 701 1571				8AWG 28/7 stranded, PVC, CAT6				8 m																		
				25	09 45 701 1572				8AWG 28/7 stranded, PVC, CAT6				9 m																		
				26	09 45 701 1573				8AWG 28/7 stranded, PVC, CAT6				10 m																		
				27	09 45 701 1574				8AWG 28/7 stranded, PVC, CAT6				15 m																		
				28	09 45 701 1575				8AWG 28/7 stranded, PVC, CAT6				20 m																		
D				29	09 45 701 1532				8AWG 27/7 stranded, PUR, CAT6				0.5 m																		
				30	09 45 701 1533				8AWG 27/7 stranded, PUR, CAT6				1 m																		
				31	09 45 701 1534				8AWG 27/7 stranded, PUR, CAT6				1.5 m																		
				32	09 45 701 1535				8AWG 27/7 stranded, PUR, CAT6				2 m																		
				33	09 45 701 1536				8AWG 27/7 stranded, PUR, CAT6				3 m																		
				34	09 45 701 1537				8AWG 27/7 stranded, PUR, CAT6				4 m																		
				35	09 45 701 1538				8AWG 27/7 stranded, PUR, CAT6				5 m																		
				36	09 45 701 1539				8AWG 27/7 stranded, PUR, CAT6				6 m																		
				37	09 45 701 1540				8AWG 27/7 stranded, PUR, CAT6				7 m																		
E				38	09 45 701 1541				8AWG 27/7 stranded, PUR, CAT6				8 m																		
				39	09 45 701 1542				8AWG 27/7 stranded, PUR, CAT6				9 m																		
				40	09 45 701 1543				8AWG 27/7 stranded, PUR, CAT6				10 m																		
				41	09 45 701 1544				8AWG 27/7 stranded, PUR, CAT6				15 m																		
				42	09 45 701 1545				8AWG 27/7 stranded, PUR, CAT6				20 m																		

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[09457002503](#) [09457002505](#) [09457002507](#) [09457002512](#)