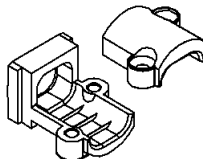
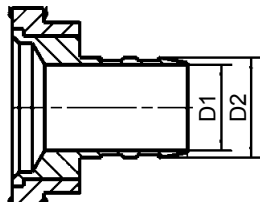
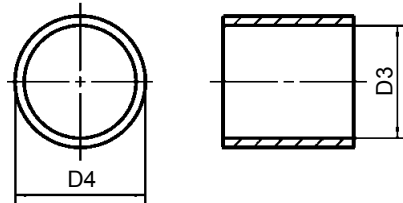


Accessories for full metal hoods

Identification	Part number		Drawing	Dimensions in mm			
Cable clamp Cable-Ø appr. 5- 7 mm Cable-Ø appr. 7-10 mm Cable-Ø appr. 9-12 mm Cable-Ø appr. 11-14 mm Cable-Ø appr. 14-16 mm	for 9-37-pole D-Sub	for 50-pole D-Sub					
	61 03 000 0141						
	61 03 000 0044						
	61 03 000 0143						
	61 03 000 0148	61 03 000 0145					
		61 03 000 0147					
Crimp flange	61 03 000 0062	61 03 000 5062	D1	D2			
	61 03 000 0063	61 03 000 5063	3.0	4.0			
	61 03 000 0064	61 03 000 5064	3.5	4.5			
	61 03 000 0065	61 03 000 5065	4.0	5.0			
	61 03 000 0066	61 03 000 5066	4.5	5.5			
	61 03 000 0166	61 03 000 5166	5.0	6.0			
	61 03 000 0067	61 03 000 5067	5.5	6.5			
	61 03 000 0068	61 03 000 5068	6.0	7.0			
	61 03 000 0069	61 03 000 5069	6.5	7.5			
	61 03 000 0070	61 03 000 5070	7.0	8.0			
	61 03 000 0071	61 03 000 5071	7.5	8.5			
	61 03 000 0165	61 03 000 5165	8.0	9.0			
	61 03 000 0072	61 03 000 5072	8.5	9.5			
			9.0	10.0			
	Crimp ferrule	61 03 000 0045		D3		D4	
		61 03 000 0046		5.0		6.0	
		61 03 000 0047		5.5		6.5	
		61 03 000 0048		6.0		7.0	
		61 03 000 0049		6.5		7.5	
61 03 000 0050		7.0		8.0			
61 03 000 0051		7.5		8.5			
61 03 000 0052		8.0		9.0			
61 03 000 0053		8.5		9.5			
61 03 000 0054		9.0		10.0			
61 03 000 0055		9.5		10.5			
61 03 000 0056		10.0		11.0			
61 03 000 0057		10.5		11.5			
61 03 000 0058		11.0		12.0			
61 03 000 0142		11.5		12.5			
61 03 000 0059		12.0		13.0			
61 03 000 0127		12.5		13.5			
61 03 000 0060		13.0		14.0			
61 03 000 0061		13.7		15.0			
		14.0		15.0			
Blanking piece for hoods		61 03 000 0042		61 03 000 0041			
Hexagonal screw thread 4-40 UNC x 17.5-8.8 with captive washer thread M3 x 17.5-8.8 with captive washer		09 67 002 9020					
		09 67 002 9019					
Knurled screw thread 4-40 UNC thread M3		09 67 002 9018					
		09 67 002 9017					

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[61030005165](#) [61030005062](#) [61030005064](#) [61030005066](#) [61030005067](#) [61030005068](#) [61030005070](#)
[61030005071](#) [61030005072](#) [61030005166](#) [61030005069](#) [61030005063](#) [61030005065](#)