
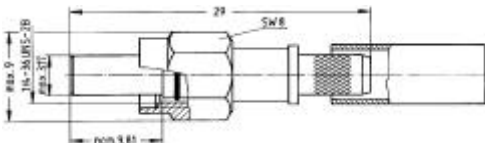
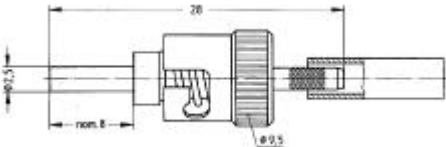
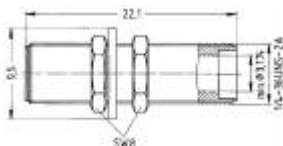


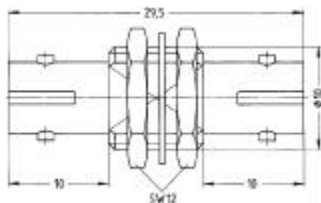

FO single connectors with glass fibres

Identification	Part-Number	Drawing	Dimensions in mm
FO connectors for GI-fibre 50-62.5/125 mm F-SMA type for cable Ø 2.8 mm FH-ST type for cable Ø 2.8 mm for SI-fibre (HCS)¹⁾ 200/230 mm F-SMA type for cabel Ø 2.8 mm FH-ST type for cable Ø 2.8 mm Versatile Link type for cabel Ø 2.2 mm	20 10 125 1212 20 10 125 2212 20 10 230 1212 20 10 230 2212 20 10 230 7111	F-SMA type  FH-ST type 	The ferrule of the FO connector for GI-fibre is ceramic Insertion loss: F-SMA GI/SI < 1.0 dB FH-ST GI/SI < 0.5 dB
¹⁾ HCS® (=Hard Clad Silica) is registered trade mark of SpecTran Corporation			
Coupling sleeve F-SMA type FH-ST type	20 80 000 1071 20 80 000 1021	 	F-SMA connector and coupling sleeve acc. to IEC 874-2 FH-ST connector and coupling sleeve acc. to IEC 874-10 CECC 86123-801

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[20102302212](#) [20101252212](#)