

Number of contacts


20–80



Male and female connectors, straight


Identification	No. of contacts	Part No.	
Male and female connectors with insulation displacement termination for discrete wire AWG 28/30 Insulation diameter (mm) $\varnothing = 0.50\text{--}0.65$		Male connector	Female connector
	20	60 13 020 5200	60 13 020 5100
	26	60 13 026 5200	
	28		60 13 028 5100
	36	60 13 036 5200	60 13 036 5100
	50	60 13 050 5200	60 13 050 5100
	68	60 13 068 5200	60 13 068 5100
	80	60 13 080 5200	60 13 080 5100

Dimensions for male connectors

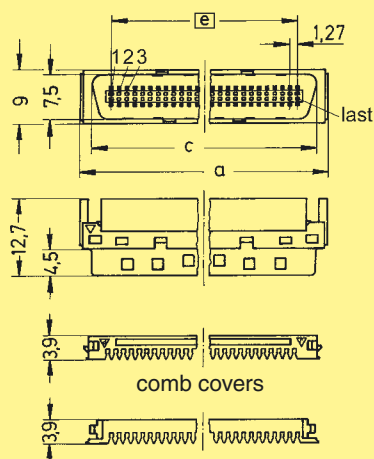

	a	c	e
20	21.24	17.55	11.43
26	25.05	21.36	15.24
36	31.40	27.71	21.59
50	40.29	36.60	30.48
68	51.72	48.03	41.91
80	59.34	55.65	49.53

Dimensions for female connectors

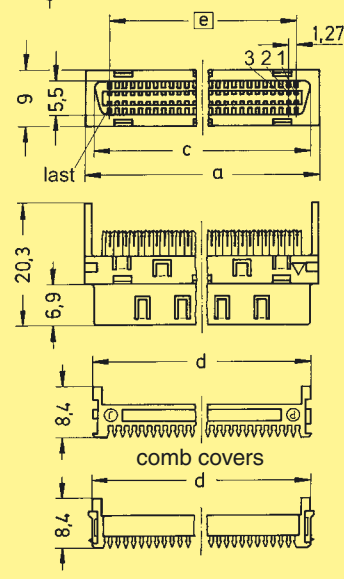

	a	c	d	e
20	19.25	16.25	16.75	11.43
28	24.33	21.33	21.83	16.51
36	29.41	26.41	26.91	21.59
50	38.30	35.30	35.80	30.48
68	49.73	46.73	47.23	41.91
80	57.35	54.35	54.85	49.53

Hoods see page 17, 18, 19
Tools see page 29, 30, 31, 32

Dimensions in mm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

60130365100