

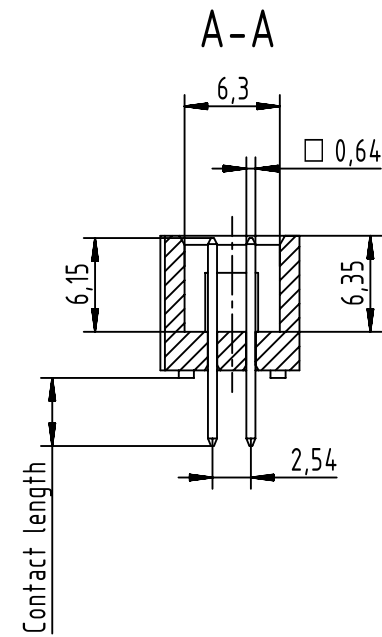
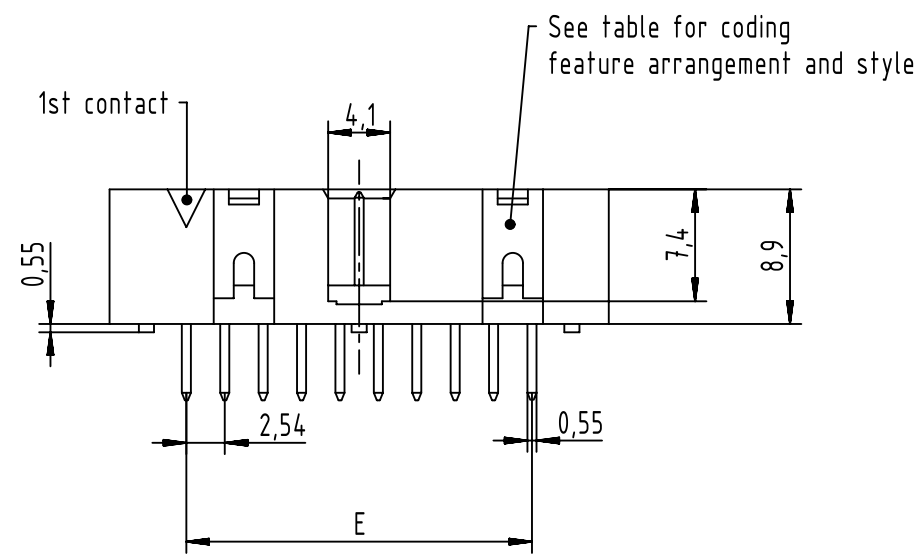
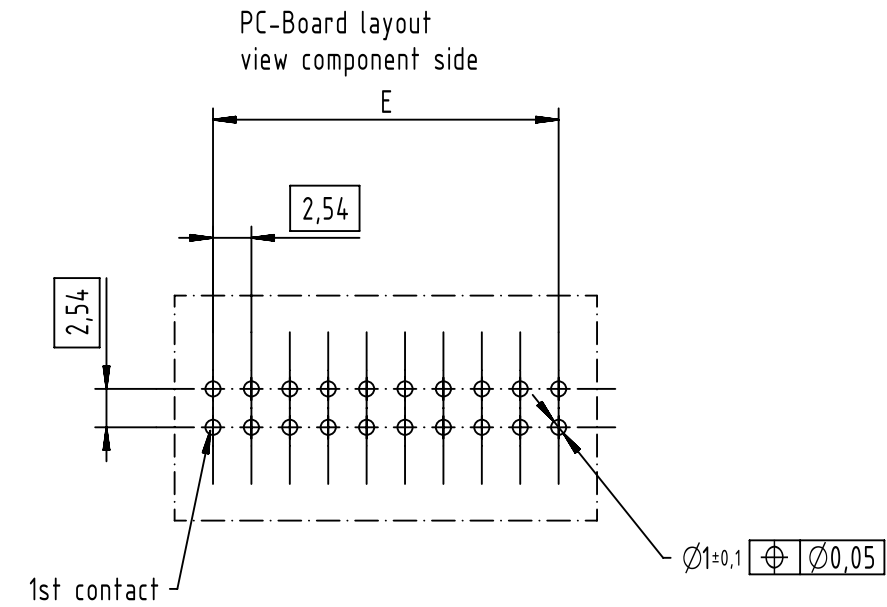


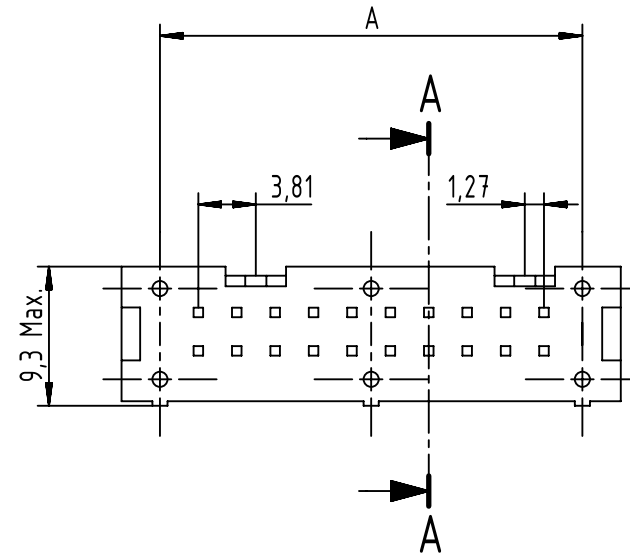

Coding style table	
	Style A: For connector 6 poles
	Style B: For connectors 10 and 14 poles
	Style C: For connectors from 16 to 64 poles

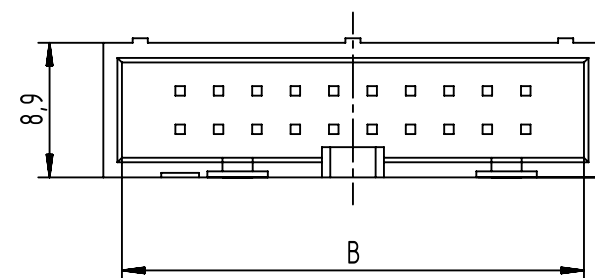

Find further technical information on drawing DS 09191130202

		All Dimensions in mm Original Size DIN A3		Scale 2:1		Free size tol.		Ref.							
								Sub.							
		All rights reserved		Created by DOUGE		Inspected by BAGDIKIAN		Standardisation HOFFMANN		Date 2013-11-04		State Final Release			
		Department EC PD - FR		Title SEK 19 male straight low profile								Doc-Key / ECM-Nr. 100541602/UGD/001/B 500000066836			
HARTING Electronics GmbH D-32339 Espelkamp				Type TB		Number 09195XXX32X						Rev. B		Page 1/2	

1				2				3				4				
A	Performance Level															
	PL3 : 50 mating Cycles No Gas Test		PL2 : 250 mating Cycles 4 days Gas Test		S4 : 0,76µm Au or equivalent PdNi						Dimensions (mm)					
	Nb of Contacts	Part Number	Part Number	Part Number	Insulator Color	Contact Lenght ±0,3(mm)	Packaging	Accessory	A Max	B	E					
	06	0919 506 7324	0919 506 6324	0919 506 5324	Beige	2,9mm	Standard (Carton Box)	-	15,4	12,78	2,54 x 2 = 5,08					
	10	0919 510 7324	0919 510 6324	0919 510 5324					20,5	17,86	2,54 x 4 = 10,16					
	14	0919 514 7324	0919 514 6324	0919 514 5324					25,6	22,94	2,54 x 6 = 15,24					
	16	0919 516 7324	0919 516 6324	0919 516 5324					28,1	25,48	2,54 x 7 = 17,78					
	20	0919 520 7324	0919 520 6324	0919 520 5324					33,2	30,56	2,54 x 9 = 22,86					
	26	0919 526 7324	0919 526 6324	0919 526 5324					40,8	38,18	2,54 x 12 = 30,48					
	30	0919 530 7324	0919 530 6324	0919 530 5324					45,9	43,26	2,54 x 14 = 35,56					
	34	0919 534 7324	0919 534 6324	0919 534 5324					51,0	48,34	2,54 x 16 = 40,64					
	40	0919 540 7324	0919 540 6324	0919 540 5324					58,6	55,96	2,54 x 19 = 48,26					
	50	0919 550 7324	0919 550 6324	0919 550 5324					71,5	68,66	2,54 x 24 = 60,96					
	60	0919 560 7324	0919 560 6324	0919 560 5324					84,2	81,36	2,54 x 29 = 73,66					
	64	0919 564 7324	0919 564 6324	0919 564 5324					89,3	86,44	2,54 x 31 = 78,74					
	B	06	0919 506 7324 001	0919 506 6324 001					0919 506 5324 001	Black	2,9mm	Standard (Carton Box)	-	15,4	12,78	2,54 x 2 = 5,08
		10	0919 510 7324 001	0919 510 6324 001					0919 510 5324 001					20,5	17,86	2,54 x 4 = 10,16
		14	0919 514 7324 001	0919 514 6324 001					0919 514 5324 001					25,6	22,94	2,54 x 6 = 15,24
		16	0919 516 7324 001	0919 516 6324 001					0919 516 5324 001					28,1	25,48	2,54 x 7 = 17,78
20		0919 520 7324 001	0919 520 6324 001	0919 520 5324 001	33,2	30,56	2,54 x 9 = 22,86									
26		0919 526 7324 001	0919 526 6324 001	0919 526 5324 001	40,8	38,18	2,54 x 12 = 30,48									
30		0919 530 7324 001	0919 530 6324 001	0919 530 5324 001	45,9	43,26	2,54 x 14 = 35,56									
34		0919 534 7324 001	0919 534 6324 001	0919 534 5324 001	51,0	48,34	2,54 x 16 = 40,64									
40		0919 540 7324 001	0919 540 6324 001	0919 540 5324 001	58,6	55,96	2,54 x 19 = 48,26									
50		0919 550 7324 001	0919 550 6324 001	0919 550 5324 001	71,5	68,66	2,54 x 24 = 60,96									
60		0919 560 7324 001	0919 560 6324 001	0919 560 5324 001	84,2	81,36	2,54 x 29 = 73,66									
64		0919 564 7324 001	0919 564 6324 001	0919 564 5324 001	89,3	86,44	2,54 x 31 = 78,74									
C		06	0919 506 7324 740	0919 506 6324 740	0919 506 5324 740	Beige	2,9mm	Tape & Reel	Vacuum Cover					15,4	12,78	2,54 x 2 = 5,08
		10	0919 510 7324 740	0919 510 6324 740	0919 510 5324 740									20,5	17,86	2,54 x 4 = 10,16
		14	0919 514 7324 740	0919 514 6324 740	0919 514 5324 740									25,6	22,94	2,54 x 6 = 15,24
		16	0919 516 7324 740	0919 516 6324 740	0919 516 5324 740									28,1	25,48	2,54 x 7 = 17,78
	20	0919 520 7324 740	0919 520 6324 740	0919 520 5324 740	33,2					30,56	2,54 x 9 = 22,86					
	26	0919 526 7324 740	0919 526 6324 740	0919 526 5324 740	40,8					38,18	2,54 x 12 = 30,48					
	30	0919 530 7324 740	0919 530 6324 740	0919 530 5324 740	45,9					43,26	2,54 x 14 = 35,56					
	34	0919 534 7324 740	0919 534 6324 740	0919 534 5324 740	51,0					48,34	2,54 x 16 = 40,64					
	40	0919 540 7324 740	0919 540 6324 740	0919 540 5324 740	58,6					55,96	2,54 x 19 = 48,26					
	50	0919 550 7324 740	0919 550 6324 740	0919 550 5324 740	71,5					68,66	2,54 x 24 = 60,96					
	60	0919 560 7324 740	0919 560 6324 740	0919 560 5324 740	84,2					81,36	2,54 x 29 = 73,66					
	64	0919 564 7324 740	0919 564 6324 740	0919 564 5324 740	89,3					86,44	2,54 x 31 = 78,74					
	D	06	0919 506 7324 741	0919 506 6324 741	0919 506 5324 741					Black	2,9mm	Tape & Reel	Vacuum Cover	15,4	12,78	2,54 x 2 = 5,08
		10	0919 510 7324 741	0919 510 6324 741	0919 510 5324 741									20,5	17,86	2,54 x 4 = 10,16
		14	0919 514 7324 741	0919 514 6324 741	0919 514 5324 741									25,6	22,94	2,54 x 6 = 15,24
		16	0919 516 7324 741	0919 516 6324 741	0919 516 5324 741									28,1	25,48	2,54 x 7 = 17,78
20		0919 520 7324 741	0919 520 6324 741	0919 520 5324 741	33,2	30,56	2,54 x 9 = 22,86									
26		0919 526 7324 741	0919 526 6324 741	0919 526 5324 741	40,8	38,18	2,54 x 12 = 30,48									
30		0919 530 7324 741	0919 530 6324 741	0919 530 5324 741	45,9	43,26	2,54 x 14 = 35,56									
34		0919 534 7324 741	0919 534 6324 741	0919 534 5324 741	51,0	48,34	2,54 x 16 = 40,64									
40		0919 540 7324 741	0919 540 6324 741	0919 540 5324 741	58,6	55,96	2,54 x 19 = 48,26									
50		0919 550 7324 741	0919 550 6324 741	0919 550 5324 741	71,5	68,66	2,54 x 24 = 60,96									
60		0919 560 7324 741	0919 560 6324 741	0919 560 5324 741	84,2	81,36	2,54 x 29 = 73,66									
64		0919 564 7324 741	0919 564 6324 741	0919 564 5324 741	89,3	86,44	2,54 x 31 = 78,74									
E		06	0919 506 7322	0919 506 6322	0919 506 5322	Beige	4,5mm	Standard (Carton Box)	-					15,4	12,78	2,54 x 2 = 5,08
		10	0919 510 7322	0919 510 6322	0919 510 5322									20,5	17,86	2,54 x 4 = 10,16
		14	0919 514 7322	0919 514 6322	0919 514 5322									25,6	22,94	2,54 x 6 = 15,24
		16	0919 516 7322	0919 516 6322	0919 516 5322									28,1	25,48	2,54 x 7 = 17,78
	20	0919 520 7322	0919 520 6322	0919 520 5322	33,2					30,56	2,54 x 9 = 22,86					
	26	0919 526 7322	0919 526 6322	0919 526 5322	40,8					38,18	2,54 x 12 = 30,48					
	30	0919 530 7322	0919 530 6322	0919 530 5322	45,9					43,26	2,54 x 14 = 35,56					
	34	0919 534 7322	0919 534 6322	0919 534 5322	51,0					48,34	2,54 x 16 = 40,64					
	40	0919 540 7322	0919 540 6322	0919 540 5322	58,6					55,96	2,54 x 19 = 48,26					
	50	0919 550 7322	0919 550 6322	0919 550 5322	71,5					68,66	2,54 x 24 = 60,96					
	60	0919 560 7322	0919 560 6322	0919 560 5322	84,2					81,36	2,54 x 29 = 73,66					
	64	0919 564 7322	0919 564 6322	0919 564 5322	89,3					86,44	2,54 x 31 = 78,74					
		06	0919 506 7322 001	0919 506 6322 001	0919 506 5322 001					Black	4,5mm	Standard (Carton Box)	-	15,4	12,78	2,54 x 2 = 5,08
		10	0919 510 7322 001	0919 510 6322 001	0919 510 5322 001									20,5	17,86	2,54 x 4 = 10,16
		14	0919 514 7322 001	0919 514 6322 001	0919 514 5322 001									25,6	22,94	2,54 x 6 = 15,24
		16	0919 516 7322 001	0919 516 6322 001	0919 516 5322 001									28,1	25,48	2,54 x 7 = 17,78
20		0919 520 7322 001	0919 520 6322 001	0919 520 5322 001	33,2	30,56	2,54 x 9 = 22,86									
26		0919 526 7322 001	0919 526 6322 001	0919 526 5322 001	40,8	38,18	2,54 x 12 = 30,48									
30		0919 530 7322 001	0919 530 6322 001	0919 530 5322 001	45,9	43,26	2,54 x 14 = 35,56									
34		0919 534 7322 001	0919 534 6322 001	0919 534 5322 001	51,0	48,34	2,54 x 16 = 40,64									
40		0919 540 7322 001	0919 540 6322 001	0919 540 5322 001	58,6	55,96	2,54 x 19 = 48,26									
50		0919 550 7322 001	0919 550 6322 001	0919 550 5322 001	71,5	68,66	2,54 x 24 = 60,96									
60		0919 560 7322 001	0919 560 6322 001	0919 560 5322 001	84,2	81,36	2,54 x 29 = 73,66									
64		0919 564 7322 001	0919 564 6322 001	0919 564 5322 001	89,3	86,44	2,54 x 31 = 78,74									

	All Dimensions in mm Original Size DIN A4	Scale 1:1	Free size tol.	Ref.
				Sub.
	All rights reserved Department EC PD - FR	Created by DOUGE	Inspected by BAGDIKIAN	Standardisation HOFFMANN
		Date 2013-11-04	State Final Release	
HARTING Electronics GmbH D-32339 Espelkamp		Title SEK 19 male straight low profile		
		Type TB	Number 09195XXX32X	Rev. B
		Page 2/2		

Doc-Key / ECM-Nr. 100541602/UGD/001/B 500000066836	
--	--

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[09195106322](#) [09195345322](#) [09195305322](#) [09195306322](#)