
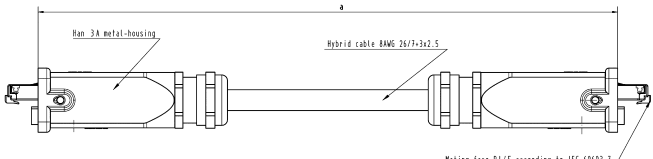
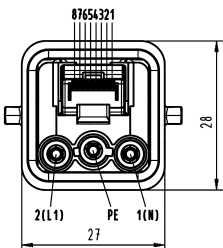


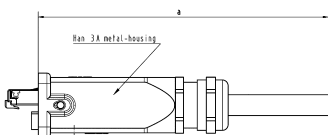

Identification	Part No.	Drawing	Dimensions in mm
Hybrid cable, double ended, 4 x 2 x AWG 26/7 + 3 x 2.5 mm² Length: a = 1 m AC version DC version a = 5 m AC version DC version a = 10 m AC version DC version a = 20 m AC version DC version	33 57 211 0010 001 33 57 211 0010 002 33 57 211 0050 001 33 57 211 0050 002 33 57 211 0100 001 33 57 211 0100 002 33 57 211 0200 001 33 57 211 0200 002	double ended  a = length 	
Hybrid cable, single ended, 4 x 2 x AWG 26/7 + 3 x 2.5 mm² Length: a = 1 m AC version DC version a = 5 m AC version DC version a = 10 m AC version DC version a = 20 m AC version DC version	33 57 111 0010 002 33 57 111 0010 001 33 57 111 0050 002 33 57 111 0050 001 33 57 111 0100 002 33 57 111 0100 001 33 57 111 0200 002 33 57 111 0200 001	Protection level: IP 65 / IP 67 Data part: Transmission properties in accordance with ISO/IEC 11801:2002: Class D single ended  a = length	
Hybrid outdoor cable Length: 10 m Length: 20 m Length: 500 m	33 57 851 0100 001 33 57 851 0200 001 33 57 851 5000 001		PVC jacket 4 x 2 x AWG 26/7 + 3 x 2.5 mm ² Outer diameter: 12 mm Min. bending radius: single: 5 x OD repeated: 10 x OD

Further cable lengths are available on request

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[33578510100001](#) [33578510200001](#) [33578515000001](#)