

1

2

3

4

A

B

C

D

A

B

C

D

MATERIAL:

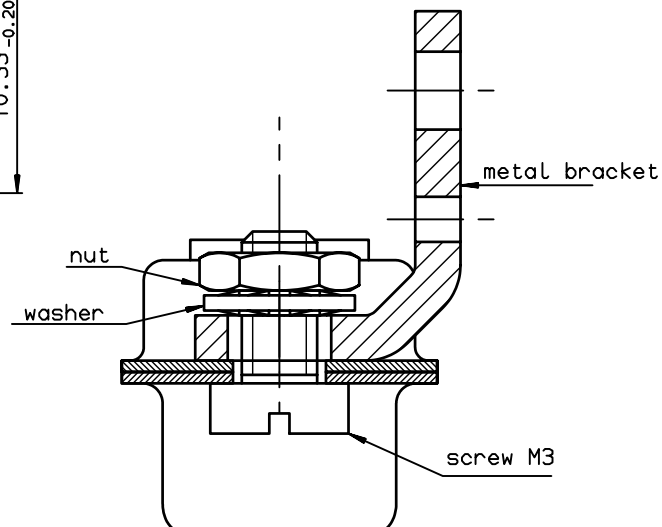
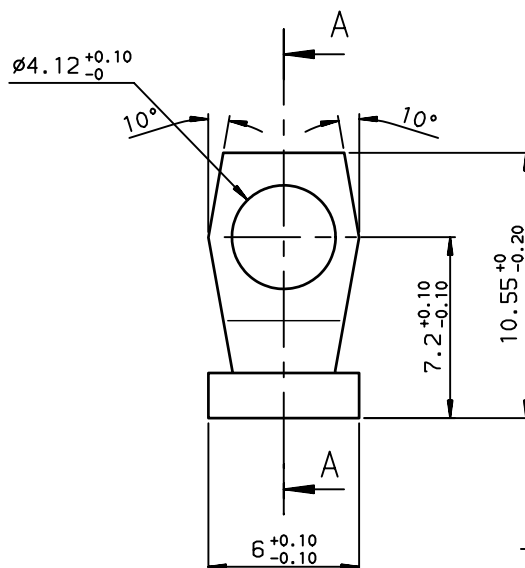
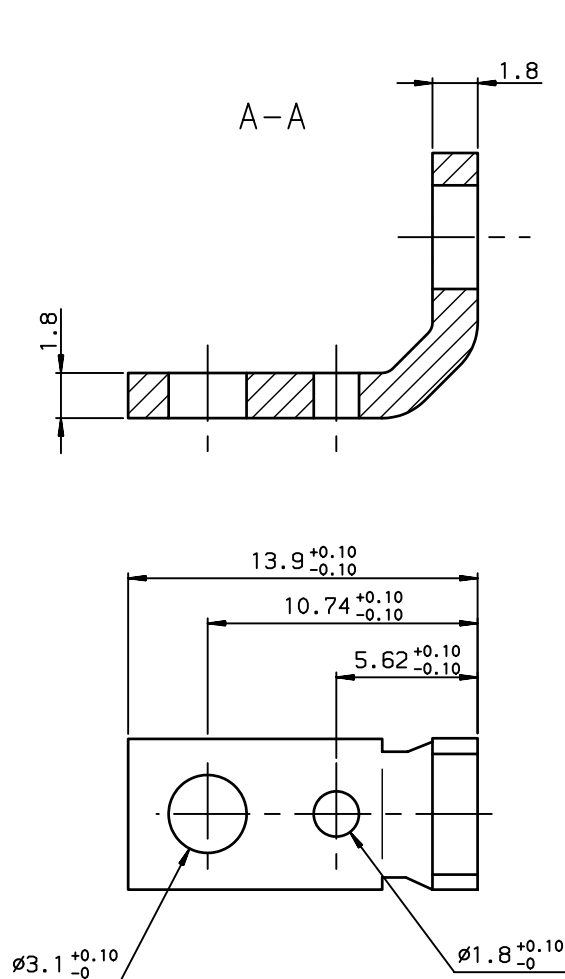
Steel . Tin Lead plating

TEMPERATURE RANGE:

-Climatic category: -55°/+125°

PACKAGING:

Per 100 pieces

BRACKET MOUNTINGPart
number

86552008TLF

NOTE:RoHS INFORMATIONS

- The "LF" products meet European union Directives and other country regulations as described in GS-22-008.
- Plating Sn (pure bright) over copper
- Packaging spec: see GS-14-920

rev	ecn no	dr	date
A	-	JOU	1998/04/10
B	LS05-0026	MPE	2005/07/08
C	LS06-0097	LGO	2006/07/28
D	LS09-0006	PCR	2009/01/08
-	-	-	-
-	-	-	-
-	-	-	-

www.fciconnect.com			surface ISO 1302	tolerance std ISO 406 ISO 1101	projection mm	size A3		Scale 5	
			TOLERANCES UNLESS OTHERWISE SPECIFIED						
Dr	Joubert	1998/04/10	ANGULAR	0.X	±0.1				
Eng	PESSON	1998/04/10	LINEAR	0.XX	±0.1				
Chr	LEGARE	1998/04/10	0.XX' ±2'	0.XXX	±0.1				
Appr	LEGARE	1998/04/10	Product family			D-SUB		Spec ref -	
			title			Dwg no		Rev.	
			METAL BRACKETS			C01-8655-1512		D	
			D SUB ACCESSORIES						
			catalog no			CUSTOMER		sheet 1 of 1	

REV F - 2006-04-17

1

2

3

4

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[FCI / Amphenol:](#)

[86552008TLF](#)